

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1001935047

Status:


Active

Overview:

Temp-Flex Microwave Coaxial Cable

Description:

Temp-Flex Foam-Core Low-Loss Flexible Microwave Cable, FEP Jacket, 1.42mm Outer Jacket Diameter, 28 AWG, 047 Style

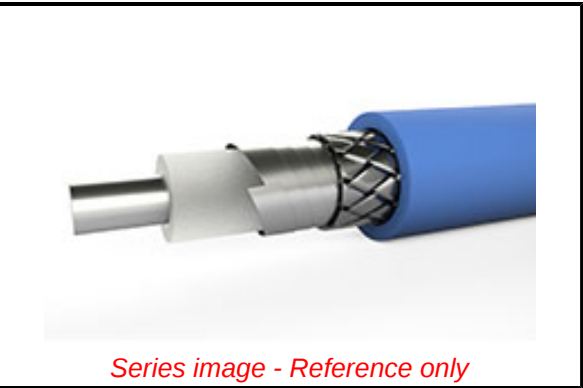

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable
Series	100193
Crimp Quality Equipment	Yes
Overview	Temp-Flex Microwave Coaxial Cable
Product Name	Temp-Flex
Taxonomy	Specialty Wire and Cable
UPC	889056677271
Physical	
Bending Radius - Minimum	6.35mm
Cable Length	30.48m min - 1067.00m max
Circuits (Loaded)	1
Color - Cable Jacket	Blue
Insulation	Foamed Fluoropolymer
Material - Outer Jacket	FEP
Net Weight	1.716/g
Outer Jacket Diameter	1.42mm
Packaging Type	Reel
Temperature Range - Operating	-65° to +165°C
Wire Size AWG	28
Wire Size mm²	0.08
Wire/Cable Type	Foam-Core Microwave Coaxial
Electrical	
Current - Maximum per Contact	Contact Molex
Voltage - Maximum	CONTACT MOLEX

Material Info

Reference - Drawing Numbers

Sales Drawing

1001935047-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

100193 Series

Use With

RF Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION