



Part Number : [1300940220](#)


Product Description : Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 38.10-44.20mm (1.500-1.740"), Approximate Break Strength 870.90kg (1920 lbs), Stainless Steel

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Part Number : 35006SS

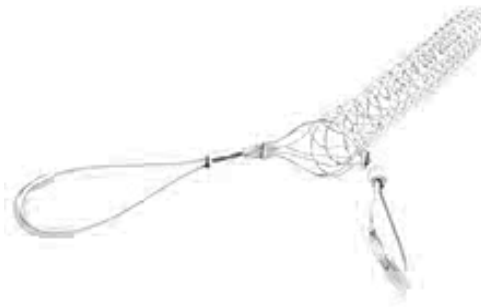

Documents and Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Not Reviewed per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 38.10-44.20mm (1.500-1.740"), Approximate Break Strength 870.90kg (1920 lbs), Stainless Steel
NEMA Rating	NEMA 4
Product Name	Standard Duty
Type	Support Grip
UPC	78678829322

Physical

Approximate Break Strength	870.90kg (1920 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	38.10-44.20mm (1.500-1.740")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Stainless Steel
Mesh Length	0.432m (17.00")
Net Weight	532.110/g
Number of Holes	N/A
O-Ring	No
Thread Size	N/A

This document was generated on May 21, 2026