

Rack Mount Locking Storage Drawer *RDRW Series*

Load rated up to 145 lbs (66 kg)

Features




- Constructed of 14 and 16 gauge steel.
- Includes front plastic pull handle locking mechanism.
- The inside drawer width is 16.12" wide.
- Complete drawer with slides, hardware, lock & two keys.
- Available in 3 depths.
- Rear support brackets are included for all depths or can be supported from the rear rack rail.
- 6-Pack of 10-32 rack screws are included.
- Finished in textured RAL9005 black or RAL 7035 light gray powder coat. Complies with the Greenguard guidelines for indoor air quality.
- Up to 145 lbs (66 kg) **load rating** when mounted to two-pair/4-post rack rails.
 - Rated for 60 lbs (27 kg) when mounted one-pair/2-post rack rails.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS and REACH compliant.
- Manufactured in North America.

Accessories

- Hardware for Rack Mounting Solutions
- Rack Equipment Installation Tool
- Wing Knob Latch



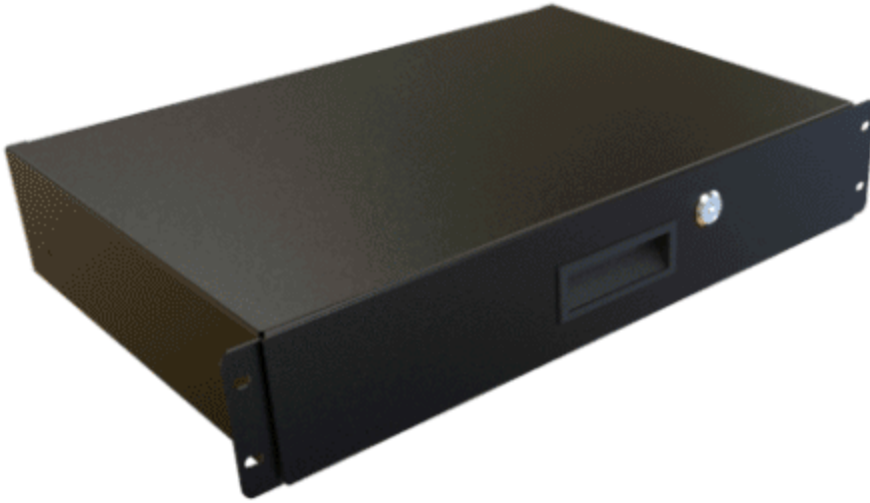

Part No.	Part No.	Overall Dimensions			Usable Dimensions		Slide	Rack	Weight
		Height	Width	Depth	Height	Depth			
RAL9005 Black	RAL 7035 Light Gray								
RDRW190031 2BK1	RDRW190031 2LG1	3.50	17.36	12.25	2.89	11.32	12.00	2U	145 lbs (65.8 kg)
RDRW190051 2BK1	RDRW190051 2LG1	5.25	17.36	12.25	4.64	11.33	12.00	3U	145 lbs (65.8 kg)
RDRW190071 2BK1	RDRW190071 2LG1	7.00	17.36	12.25	6.39	11.33	12.00	4U	145 lbs (65.8 kg)
-	RDRW190081 2LG1	8.75	17.36	12.25	8.14	11.33	12.00	5U	145 lbs (65.8 kg)
RDRW190031 6BK1	RDRW190031 6LG1	3.50	17.36	16.25	2.89	15.33	16.00	2U	129 lbs (58.5 kg)
RDRW190051 6BK1	RDRW190051 6LG1	5.25	17.36	16.25	4.64	15.33	16.00	3U	129 lbs (58.5 kg)
RDRW190071 6BK1	RDRW190071 6LG1	7.00	17.36	16.25	6.39	15.33	16.00	4U	129 lbs (58.5 kg)
RDRW190081 6BK1	RDRW190081 6LG1	8.75	17.36	16.25	8.14	15.33	16.00	5U	129 lbs (58.5 kg)
-	RDRW190121 6LG1	12.25	17.36	16.25	11.64	15.33	16.00	7U	129 lbs (58.5 kg)
RDRW190032 2BK1	RDRW190032 2LG1	3.50	17.36	22.25	2.89	21.33	22.00	2U	107 lbs (48.5 kg)
RDRW190052 2BK1	RDRW190052 2LG1	5.25	17.36	22.25	4.64	21.33	22.00	3U	107 lbs (48.5 kg)
RDRW190072 2BK1	RDRW190072 2LG1	7.00	17.36	22.25	6.39	21.33	22.00	4U	107 lbs (48.5 kg)
RDRW190082 2BK1	RDRW190082 2LG1	8.75	17.36	22.25	8.14	21.33	22.00	5U	107 lbs (48.5 kg)
RDRW190122 2BK1	RDRW190122 2LG1	12.25	17.36	22.25	11.64	21.33	22.00	7U	107 lbs (48.5 kg)

Qty Included	Description	Replacement Part No.
1	Drawer	

Qty Included	Description	Replacement Part No.
2	Keys for lock	
8	10-32 x 0.625in screw	
2	Rear drawer support bracket	
4	8-32 Keps nut	
1	Assembly and installation instructions	

Tags: **Lockable Storage Drawer**

Data subject to change without notice.

© 2026. Hammond Manufacturing Ltd. All rights reserved.