

Thermofit[®] Molded Parts

Specification Control Drawing

Limited Distribution

Part Number : 202D232-X-22
Description : Boot, Straight, With Lip

NOTES

- All dimensions are in $\frac{\text{inches}}{[\text{millimeters}]}$
- Dimensions appearing in table are as follows:
a - As Supplied
b - After Unrestricted Recovery
- Coating is optional. As supplied dimensions appearing in table are for uncoated parts. When coating is added, entry diameters will be reduced by .06 max.

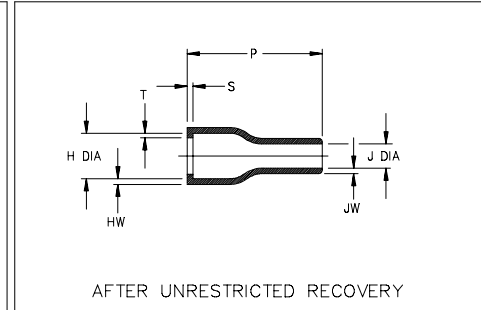
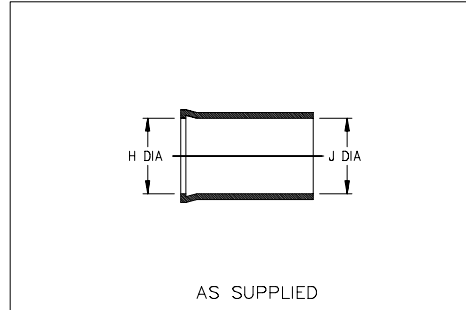


TABLE OF DIMENSIONS									
PART NUMBER	H		J		P ±10% b	S Ref b	T Ref b	HW ±20% b	JW ±20% b
	Min	Max	Min	Max					
	a	b	a	b					
202D232-X-22	1.16 [29,5]	.74 [18,8]	1.16 [29,5]	.33 [8,4]	3.50 [88,9]	.12 [3,0]	.04 [1,0]	.07 [1,78]	.045 [1,1]

Raychem

RAYCHEM CORPORATION
300 CONSTITUTION DRIVE
MENLO PARK, CALIFORNIA 94025

Revision : A
Date : 5/3/00

Part Number : 202D232-X-22
Description : Boot, Straight, With Lip

Thermofit[®] Molded Parts

Specification Control Drawing

Limited Distribution

Part Number : 202D232-X-22
Description : Boot, Straight, With Lip

COMPATABILITY CHART					
MATERIAL DASH NO.	MATERIAL DESCRIPTION	RT SPEC	COATING SLASH NO.	COATING S NO.	COATING DESCRIPTION
-3	Polyolefin, Semi-rigid	RT-301	N/A		

ORDERING INFORMATION

Base part number 202D232 -X -22 /XX

Material dash number (See Compatability Chart)

Modification number (If necessary, see front of scd binder for a complete list)

Adhesive slash number (If necessary, see Compatability Chart)

If this document is printed it becomes uncontrolled.
Check for the latest revision.

THIS DRAWING IS SUBJECT TO CHANGE WITHOUT NOTICE; CONSULT YOUR
NEAREST FIELD REPRESENTATIVE FOR CURRENT REVISION

Raychem

RAYCHEM CORPORATION
300 CONSTITUTION DRIVE
MENLO PARK, CALIFORNIA 94025

Revision : A
Date : 5/3/00

Part Number : 202D232-X-22
Description : Boot, Straight, With Lip
CAD FILE MP00061