





DB UNLIMITED

Part Number:	SM270908-1	
	DRAWN CJ	1/6/2017
	CHECKED P.D.	1/6/2017
Description:	Dynamic Speaker	
	APPROVED J.S.	1/6/2017
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

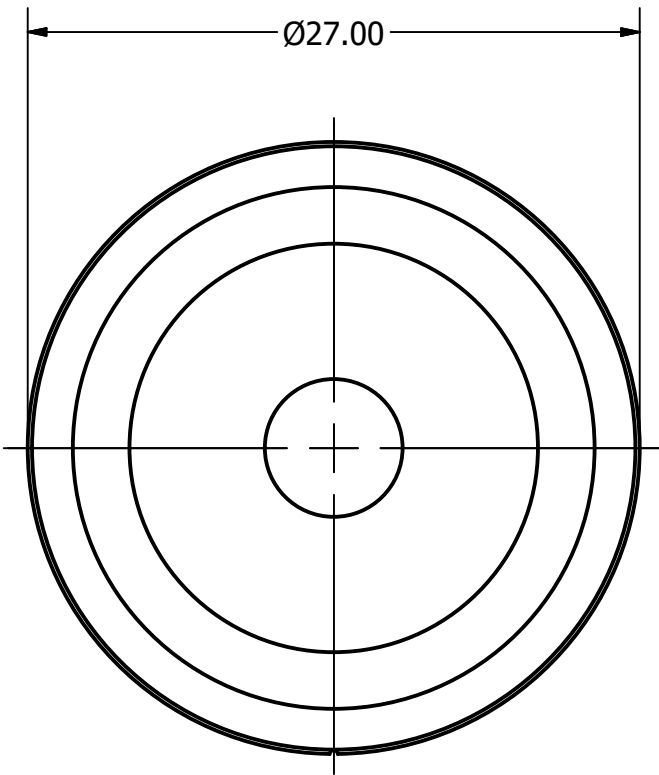

Side View

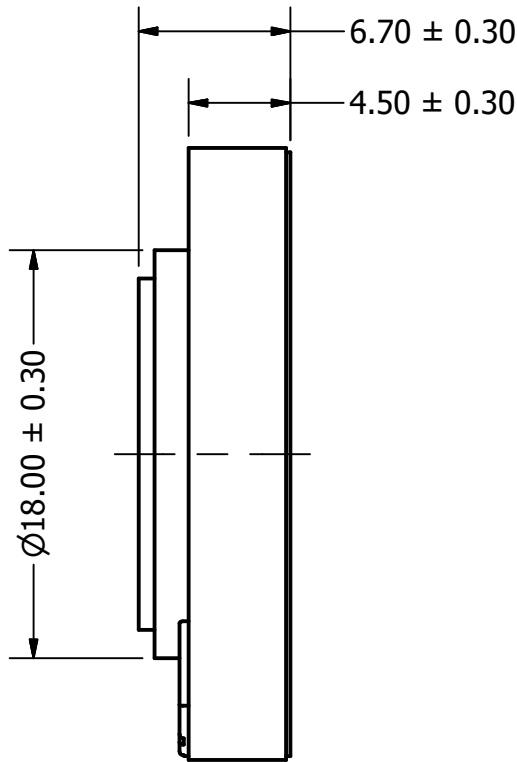

Bottom View

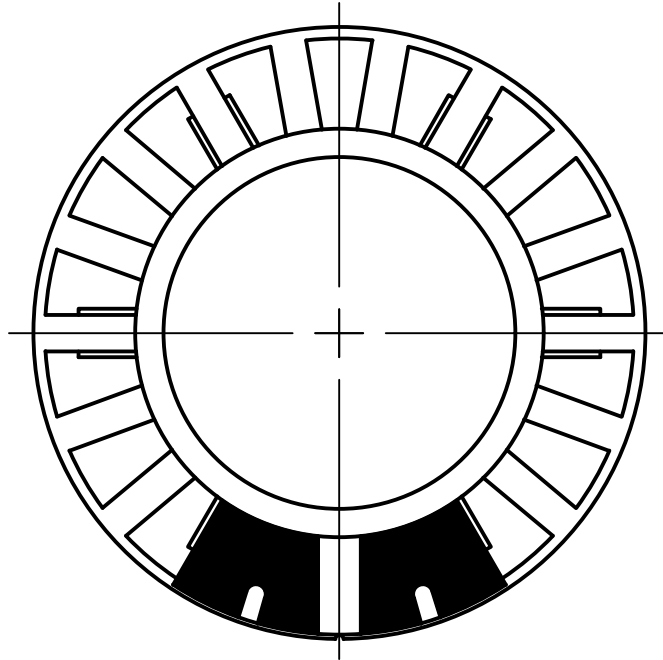

Items	Specifications	Conditions				
Sound Pressure Level	93	dB (@ 10cm)				
Resonant Frequency	950	Hz				
Frequency Range	950 ~ 20,000	Hz				
Nominal Power	0.25	W				
Max. Power	0.5	W				
Impedance	8	Ω				
Cone Material	Mylar					
Mount Type	Flush Mount					
Storage Temperature	-40 ~ +66	°C				
Operating Temperature	-40 ~ +66	°C				
Weight	6.4	g				
			REVISION HISTORY			
			REV	DESCRIPTION	DATE	APPROVED
				Released from Engineering	10/21/2013	J.S.
			1	Updated to new template	1/6/2017	J.S.
			NOTES			
			1) All dimensions are in mm unless otherwise noted			
			2) All tolerances are ± 0.5 mm unless otherwise noted			
			3) All parts meet RoHS			
			4) Subject to change or redrawn without notice			