


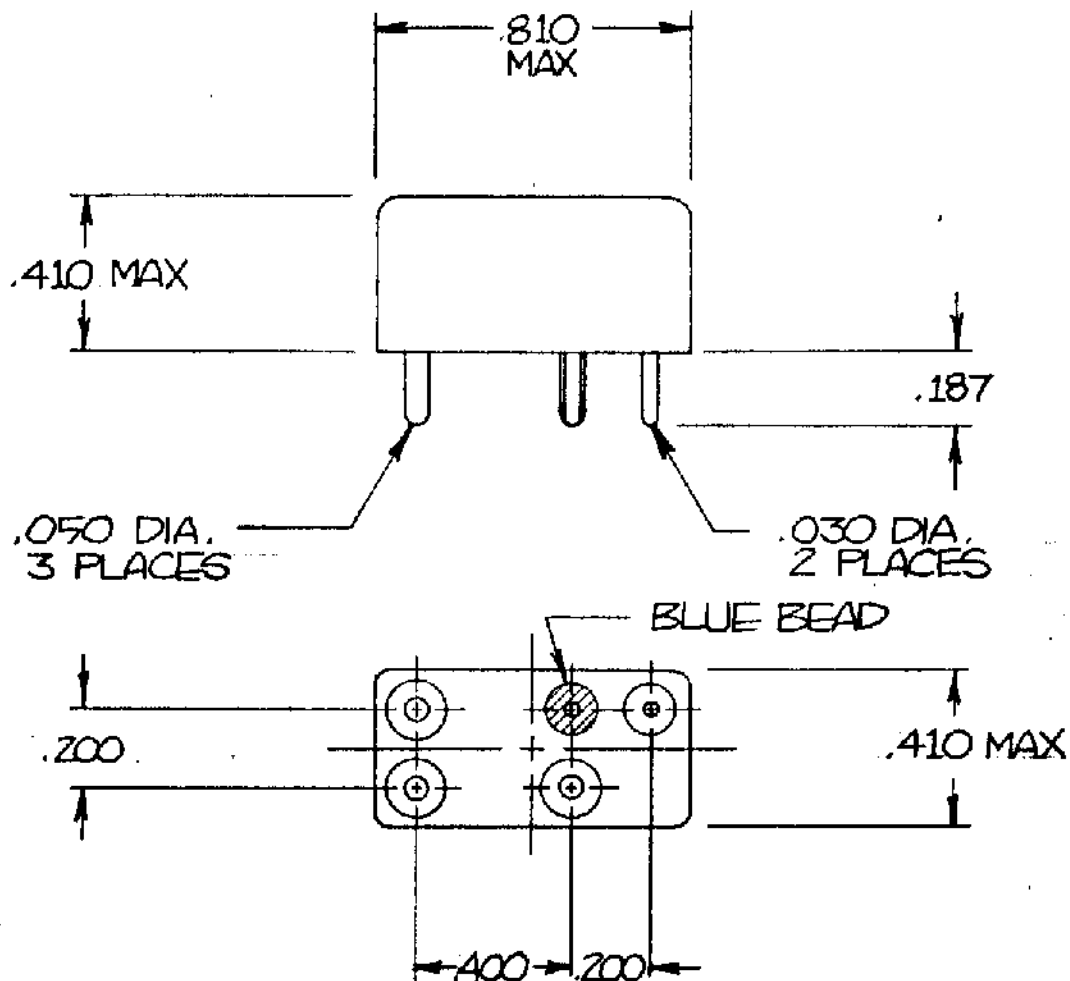

COIL:


RESISTANCE 700 Ω $\pm$ 10 %
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 1.5 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 5 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: DIELECTRIC - 1000 VRMS EXCEPT
500 VRMS ACROSS OPEN CONTACTS.

CUSTOMER DATA SHEET

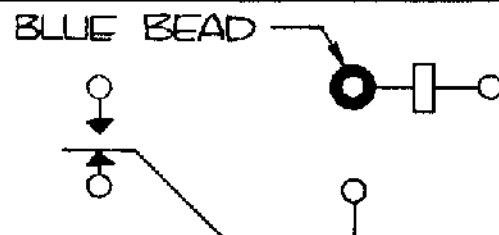

CONTACT RATING: 10 AMP/28 VDC
RESISTIVE 50,000 OPERATIONS

DR. R.B. 1-14-91 CK.1/14/91 JMB



Communications
Instruments, Inc.

CUST. C.I.I. STD.
 CUST. NO. _____

TYPE "C" RELAY

CAW-1C-24B