

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190730032

Status:


Active

Overview:

Solderless Terminals

Description:

Avikrimp Ring Tongue Terminal for 18 to 22 AWG Wire, Stud Size 3/8" (M9), Length 32.00mm

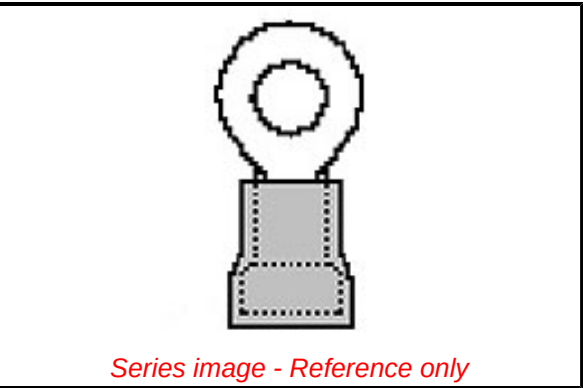

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19073
Comments	Type II Insulated
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	Avikrimp
Type	Ring
UPC	800753075177
Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	1.239/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	3/8" (M9)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.60mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	AA-826-38
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19073-003

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19073 Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
PremiumGrade Hand Crimp Tool	640010100
Crimp Head for the AT-200 Pneumatic Hand Tool	640050100
ServiceGrade Hand Crimp Tool	640160036

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION