


# Pocket Fold-up Thermometer

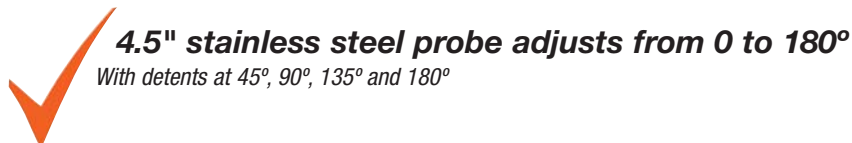

**4.5" stainless steel probe adjusts from 0 to 180°**

*With detents at 45°, 90°, 135° and 180°*

## Features:

- Wide °C/°F switchable temperature range  
-58 to 572°F (-50 to 300°C)
- Fold up probe 4.5" (114mm) adjusts from 0° to 180° for  
best measurement and viewing angle
- Large LCD display with 0.1 degree resolution
- Auto power off after 1 hour or  
when probe is placed in stored position
- Data Hold and Min/Max recordings
- Fast response time — one second  
under normal conditions
- Complete with wrist strap and one AAA battery



| Specifications |                                            |
|----------------|--------------------------------------------|
| Range          | -58 to 572°F (-50 to 300°C)                |
| Accuracy       | ±1.8°F (-22 to 482°F); ±1°C (-30 to 250°C) |
| Resolution     | 0.1°/1° resolution                         |
| Dimensions     | 6.1 x 2.0 x 0.8" (154 x 50 x 20mm)         |
| Weight         | 2.5oz (71g)                                |

## Ordering Information:

39272 .....Pocket Fold-up Thermometer  
409992 .....Vinyl Pouch Carrying Case

