

Part Number : [1201000004](#)


Product Description : D-Sub Connector without Diagnostics Ports, 90° Angle

Series Number : 120100

Status : Active

Product Category : Circular Industrial Connectors

Engineering Part Number : MA9D00-32

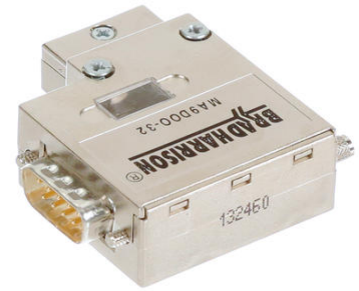


Documents and Resources

Drawings

[1201000004 sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per ED/01/2018 (15 January 2018)
EU RoHS	Compliant with Exemption 6(a)-I; 6(c) per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

UKCA - Declaration of Conformity

CE - Declaration of Conformity

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	120100
Description	D-Sub Connector without Diagnostics Ports, 90° Angle
IP Rating	IP40
Product Name	D-Sub
Type	Field Attachable Connector
UPC	78678850120

Electrical

Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	N/A
Keyway	None
Material - Connector Body	ABS
Material - Contact	Copper Alloy
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	22.679/g

Orientation	90° Angle
Poles	N/A
Temperature Range - Operating	0° to +60°C
Wire Size (AWG)	N/A

This document was generated on May 25, 2026