

1701140201

Downloaded from Arrow.com.

.079"x.079" (2.0mm) IDC Socket Connector

For 1.0mm Center Flat Ribbon Cable



APPLICATION AND FEATURES

1. FTF-Series Flat Cable connector is designed for which require small and light internal connector.
2. High quality dual beam phospher bronze contacts.
3. Mate with 2.0mm pitch and [] 0.5mm pin Header e.g.

SPECIFICATIONS

Current Rating:	1 Amps
Insulator resistance:	5000 Megohms min. 500 V DC for 1 minutes.
Dielectric withstanding:	AC 500 V for 1 minutes.
Operating Temperature:	-40 ° + 105 °C
Contact Material:	Bronze or Phosphor bronze
Insulator Material:	Nylon. UL 94V-0

© Standard:Nylon-46

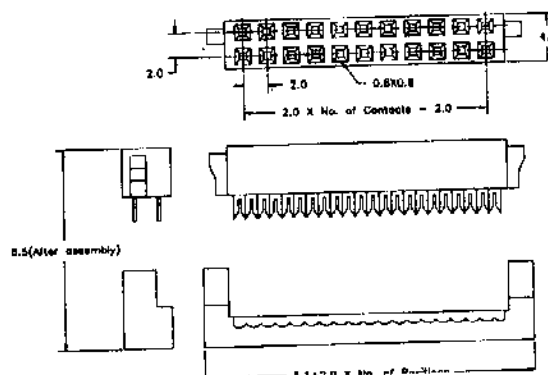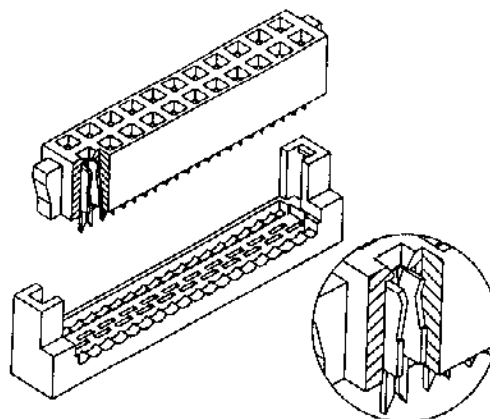

unit:mm

How to order Please replace "X" with appropriate coding listed in the tables below

FTF - XX - XX

Number of Contacts

No. of contact = Code
20
26
40
44
50


Contact Plating

Definition	Code
Tin plated:	01
Gold plated:	
flash	02
10 μ"	10
30 μ"	30


Note:

© Standard:
Gold Flash

© Optional plating on request, advise
microinch thickness.

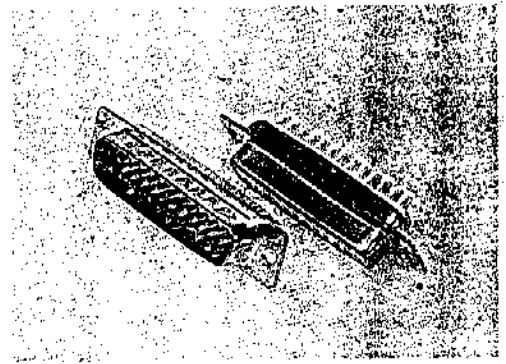

707 series D-SUB SOLDER WIRE TYPE

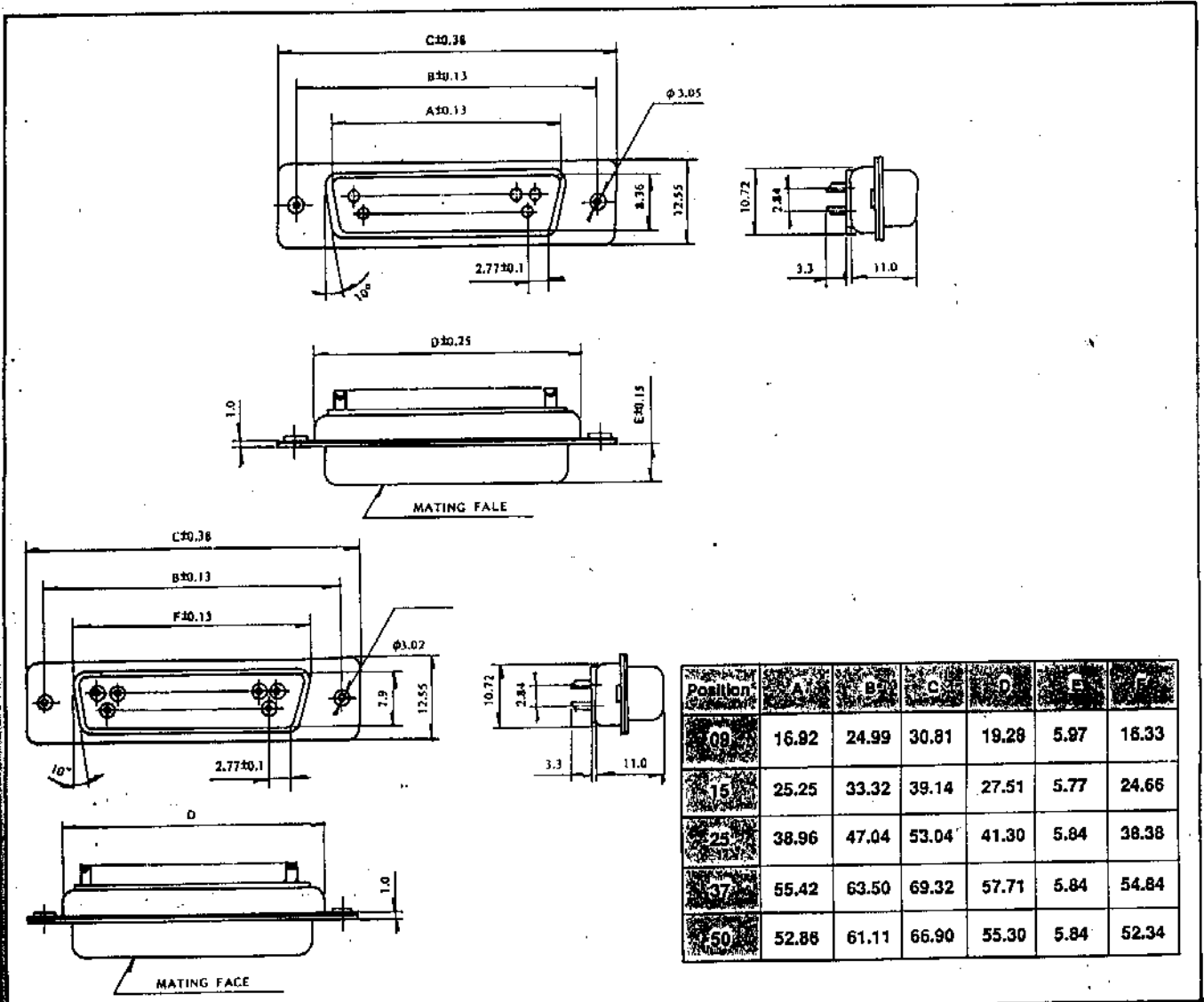

Ordering

707—09 M

M: Male
F: Female

Position