

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210230085](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form C-8mm, PG7 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Flat Gasket, Bulk Pack Mounted

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-121024-C05-001 \(PDF\)](#)


General
Product Family Field Attachable / Accessories
Series [121023](#)
Form C - 8mm
IP Rating IP65, IP67
Material - Contact Brass
Overview [mPm DIN Valve Connectors](#)
Product Name mPm
Type Field Attachable Connector
UPC 883906248840

Physical
Cable Diameter N/A
Coupling Type Internal Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polypropylene
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 9.777/g
Orientation 90° Angle
Pitch - Mating Interface 8.00mm
Poles 2
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 16.0A
Voltage - Maximum 250V AC / 300V DC

Material Info
Engineering Number C05207N62

Reference - Drawing Numbers
Packaging Specification PK-121024-C05-001
Sales Drawing SD-121023-007

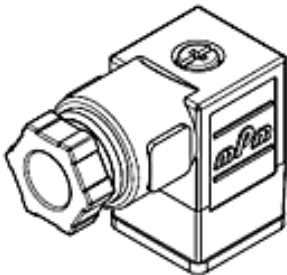

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - ED/88/2018 (15 January 2019)	
lead	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121023](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION