

Products

Part Number Search

Send

Hot Product



High SNR Microphone

10*4.5

[More info](#)



Array Microphone

24 x 8 x 2.8

[More info](#)

NEWS

▶ ? electronica 2010 ?
Hall B6, Booth
No.118 **NEW** ..[More info](#)

▶ ? TAITRONICS
2010? Taipei World
Trade Center
Nangang Exhibition
Hall,Booth
No.L1019/1021 **NEW**
..[More info](#)

▶ KINGSTATE Ultra-
Thin ESL Speaker
and Danish AM3D
Audio Software Demo
Event Successfully
Held On May 12,
2010 **NEW** ..[More info](#)

Magnetic Indicator(Internal Circuitry Type)

Wire Type

KSG6612



PRINT


Shape

KSG6612




Operating Voltage Range(VDC)	8~16
Current Consumption (mA)	Max..25@12VDC
Sound Pressure Level (dBA)	Min.79dBA@30cm@12VDC
Tone	Continuous
Operating Temperature (?)	-20~+60
Storage Temperature (?)	-30~+70
Weight (Gram)	10.7
Material	ABS

Dimension

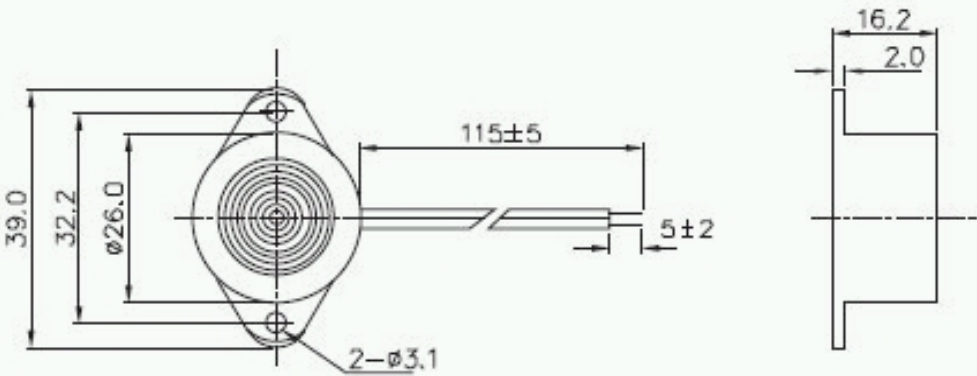

Tol : ±0.5 Unit : mm

Characteristic / Schematic Diagram

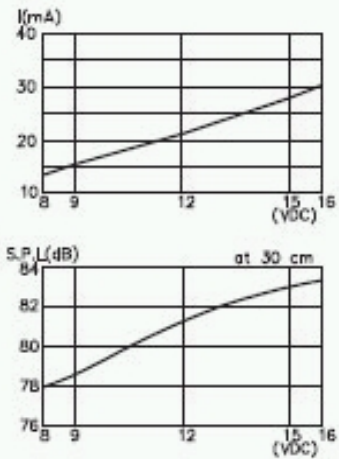

Back

TOP

