




**Part Number :** [512965494](#)

**Product Description :** Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 54 Circuits, Gold (Au) Contact Plating

**Series Number :** 51296

**Status :** Not Recommended For New Design

**Product Category :** FFC / FPC Connectors

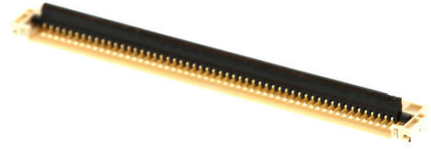

---

## Documents and Resources

### Drawings

[512965494 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

### Specifications


[SPK-51296-007-001.pdf](#)

[PS-51296-003-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

---

## Part Details

### General

Status	Not Recommended For New Design
Category	FFC / FPC Connectors
Series	51296
Description	Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 54 Circuits, Gold (Au) Contact Plating
Product Name	Easy-On
UPC	822350198332

### Agency

UL	E29179
----	--------

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

### Physical

Actuator Type	Front Flip
---------------	------------

Circuits (Loaded)	54
Color - Resin	Beige, Black
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	1.30mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	249.341/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	No
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15020</u>
0.50mm Pitch Premo-Flex FFC Jumpers	<u>15120</u>

---

This document was generated on Jun 02, 2026