

C6, Cast Bronze Clamp, Armored Cable to Water Pipe

By Burndy
Catalog # [C6](#)

Cast Bronze Clamp, Armored Cable to Water Pipe, 10 AWG - 2 AWG (Str.), 1/2" - 1" Water Pipe, pipe clamp: 50 in-lb.

Features

Connects Armored Cable to Water Pipe

Application

For Connecting Armored Cable To Water Pipe

General


Catalog Number	C6
EU RoHS Indicator	Yes
Hardware Type	Zinc Plated
Material	Bronze Alloy
Material - Hardware	Zinc Plated Steel
Plated	Y
Plating Type	Zinc
Sub Brand	CLAMP
Trade Name	N
Type	Ground Clamp
UPC	781810142394
UPC 12 Digit	7818101423944

Dimensions

Dimension - Height inch	1.60 in
Dimension - Height mm	40.6 mm
Dimension - L Length Overall mm	59 mm
Dimension - Length Overall inch	2.34 in
Dimension - Pad Width inch	0.63 in
Dimension - Thread Size	-
Dimension - Width inch	1.06 in
Dimension - Width mm	27 mm

Conductor Related

Conductor - Armored Cable Size	Y
Conductor - Copper Solid Size	8 AWG; 7 AWG; 6 AWG; 5 AWG; 4 AWG; 3 AWG; 2 AWG

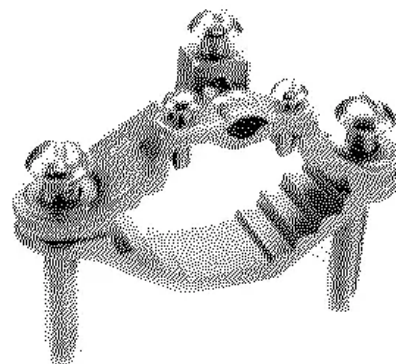

Conductor - Copper Solid Size Range	8 AWG-2 AWG
Conductor - Copper Str Size	10 AWG; 9 AWG; 8 AWG; 7 AWG; 6 AWG; 5 AWG; 4 AWG; 3 AWG; 2 AWG
Conductor - Copper Str Size Range	10 AWG - 2 AWG
Conductor - Pipe EMT Size	3/8 in; 1/2 in; 3/4 in; 1 in
Conductor - Pipe EMT Size Range	3/8 in-1 in
Conductor Type	<ul style="list-style-type: none">CU C Str-SizeCU C Solid-SizePipe EMT-Size

Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Recognized	N
Certification - cULus	N
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_C6_LineArt](#)
[Sales Drawings - sc210662-01](#)
[Specifications - C6](#)