

10.0mm Medium Spot Top Lens TIR (10417)

Email this page

Email this page

Download as pdf

Download as pdf



Part no.	10417
Drawing no.	60553
Family	10mm
Type	TIR
Diameter	10.0
Beam	Medium Spot
Finish	Top Lens



 
 
 
LEDs & Performances

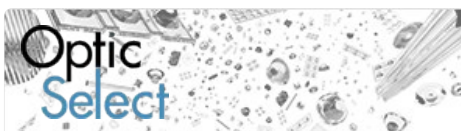
Select LED to view available holders

Columns

Columns

Manu.	Performance Data	Images	IES/STP
-------	------------------	--------	---------

 Bridgelux SMD 3030 Gen2 White	Eff: 91.5 FWHM: 15 x 18 Cd/lm: 7.6	 	View
 Cree Xlamp CSP XD16 Cool White	Eff: 91 FWHM: 17 Cd/lm: 6.3	 	View
 Cree Xlamp XB-D White	Eff: 84.2 FWHM: 19 Cd/lm: 7.9	 	View
 Cree Xlamp XB-H White	Eff: 89.5 FWHM: 22 Cd/lm: 5.7	 	View



Search by LED/Light Engine manufacturer

Philips Fortimo	LG Innotek
Citizen	Osram OS
Broadcom	Cree
Everlight	Osram DS
Lextar	Toshiba
Nichia	Sharp
LUMILEDS	Stanley
Samsung	LEDengin
Plessey	Seoul
Bridgelux	Tridonic
Luminus Devices	Lite-On

Optic Select search by optic type

Fibre Coupling	Reflector
Strip	Silicone
Side Emitter Strip	Freeform
Hybrid	Bubble
TIR	Side Emitter

 Search by part number

 Find your local distributor

 Large orders

 Custom design

Quick Enquiry

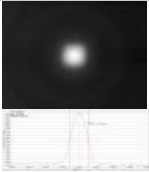
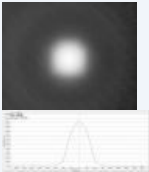
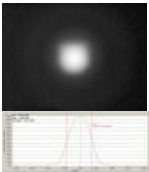
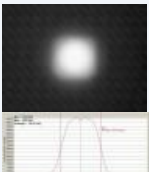
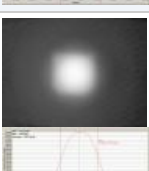
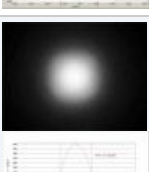
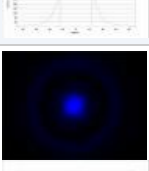
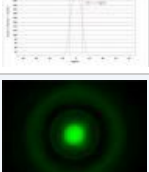
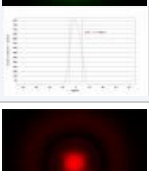
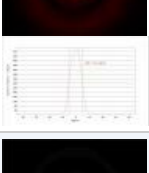
name

company name

phone number

email

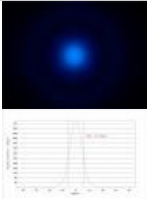
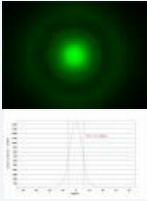
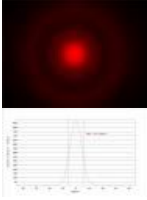
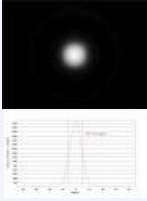
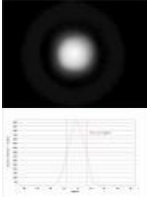
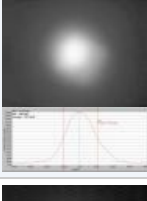
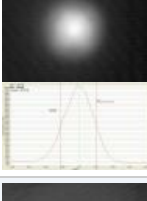
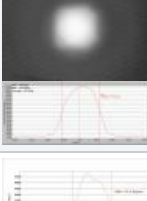
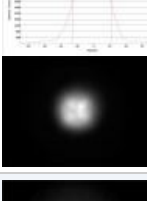
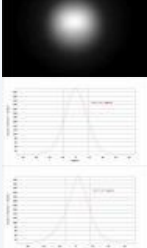
message

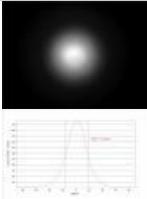
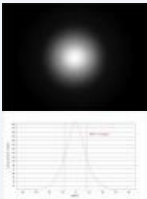
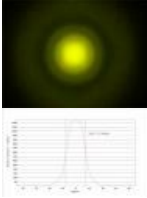
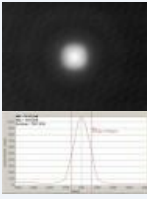
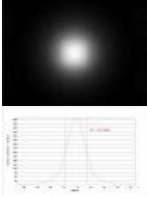
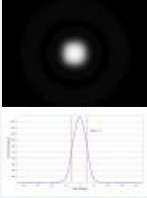
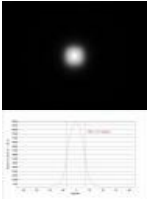
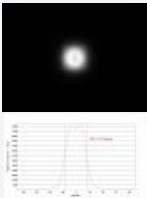
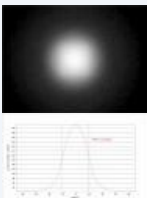
Manu.	Performance Data	Images	IES/STP
CREE * LED Solutions Provider Cree XLamp XP-C White	Eff: 87.4 FWHM: 10 Cd/lm: 22.7		View
CREE * LED Solutions Provider Cree XLamp XP-E White	Eff: 88.7 FWHM: 16 Cd/lm: 9.8		View
CREE * LED Solutions Provider Cree XLamp XP-E2 White	FWHM: 16 Cd/lm: 12.7		View
CREE * LED Solutions Provider Cree XLamp XP-G White	Eff: 87.3 FWHM: 24 Cd/lm: 4.9		View
CREE * LED Solutions Provider Cree XLamp XP-G2 White	FWHM: 23 Cd/lm: 6.2		View
CREE * LED Solutions Provider Cree XLamp XP-G3 White	Eff: 86 FWHM: 25 Cd/lm: 3.37		View
CREE * LED Solutions Provider Cree XLamp XQ-A Blue	Eff: 89 FWHM: 10 Cd/lm: 26.7		View
CREE * LED Solutions Provider Cree XLamp XQ-A Green	Eff: 89.5 FWHM: 10 Cd/lm: 26		View
CREE * LED Solutions Provider Cree XLamp XQ-A Red	Eff: 89.5 FWHM: 10 Cd/lm: 24.8		View
CREE * LED Solutions Provider Cree XLamp XQ-A White	Eff: 86 FWHM: 11 Cd/lm: 22.06		View

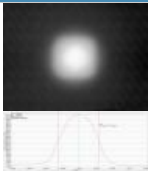
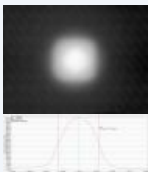
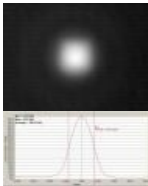
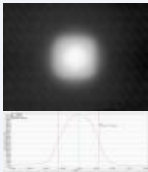
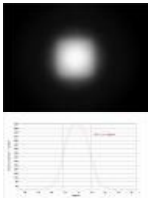
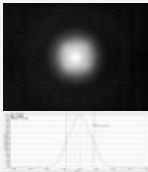
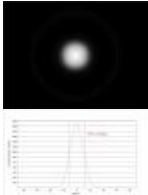
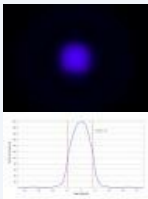
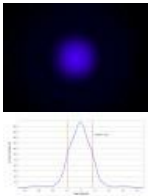
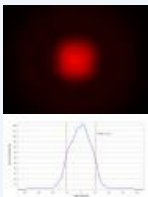
Submit

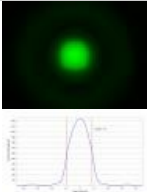
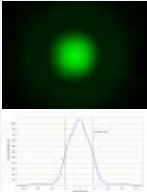
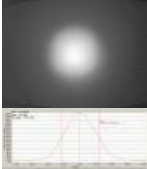
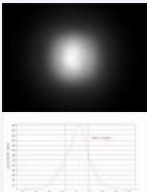
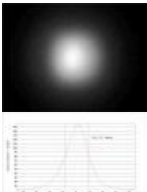
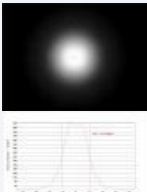
 
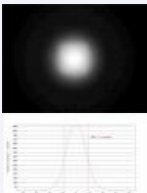
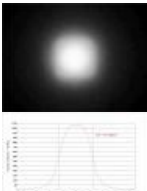
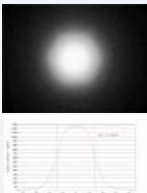
Call us for more information

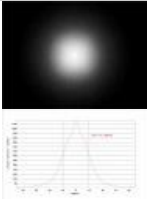
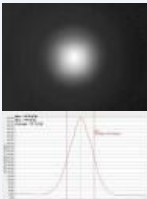
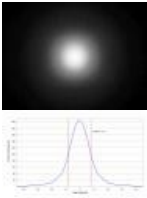
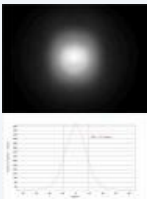
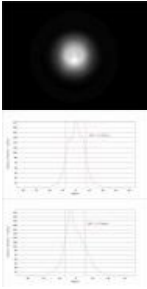
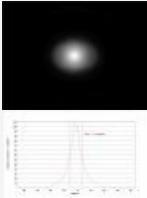
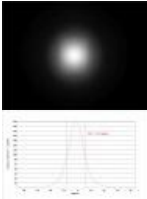
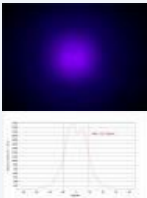
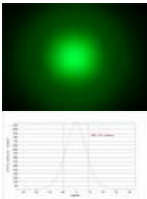
+44 1753 575 011

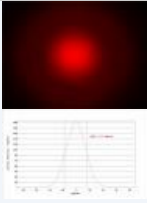
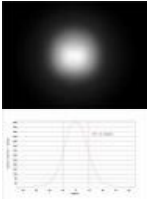
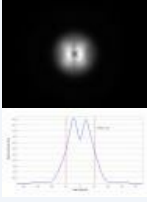
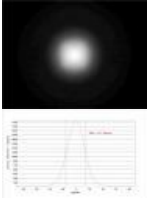
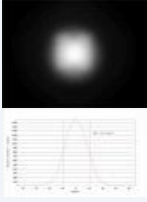
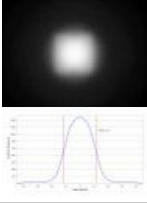
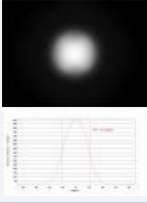
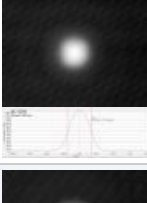
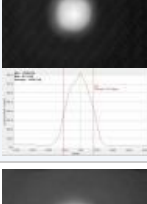
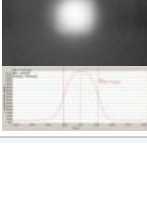
Manu.	Performance Data	Images	IES/STP
CREE * LED Solution Provider Cree XLamp XQ-E HI Blue	Eff: 89.5 FWHM: 11.5° Cd/lm: 14.7		View
CREE * LED Solution Provider Cree XLamp XQ-E HI Green	Eff: 90 FWHM: 12 Cd/lm: 14.6		View
CREE * LED Solution Provider Cree XLamp XQ-E HI Red	Eff: 90.5 FWHM: 12 Cd/lm: 16.2		View
CREE * LED Solution Provider Cree XLamp XQ-E HI White	Eff: 87 FWHM: 11 Cd/lm: 15.9		View
CREE * LED Solution Provider Cree XLamp XQ-E White	Eff: 87 FWHM: 15 Cd/lm: 9.3		View
CREE * LED Solution Provider Cree XLamp XT-E White	FWHM: 22 Cd/lm: 5.6		View
EVERLIGHT Everlight Shuen White	Eff: 85 FWHM: 21 Cd/lm: 5.2		View
LG Life's Good LG 3535LG White	FWHM: 23 Cd/lm: 2.1		View
LITEON Lite-On R38386AS - S R38 IR	Eff: 91 FWHM: 24 Cd/lm: 4.5		View
LUMILEDS LUMILEDS LUXEON 3030 (LUXEON) White	Eff: 86 FWHM: 19 x 15 Cd/lm: 5.26		View

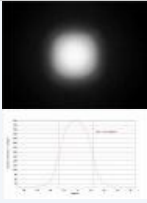
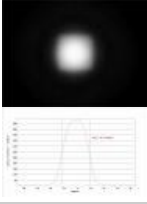
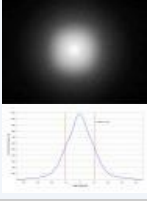
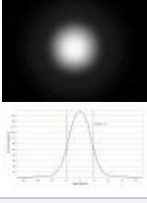
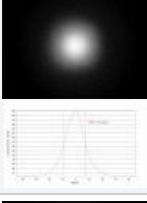
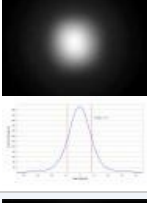
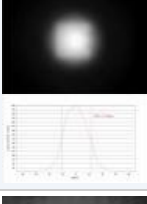
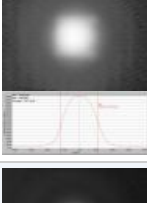
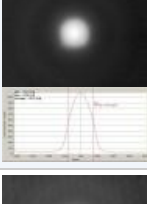
Manu.	Performance Data	Images	IES/STP
 LUMILEDS LUXEON 3535 HV White	Eff: 87.2 FWHM: 16 Cd/lm: 6.33		View
 LUMILEDS LUXEON 3535 L White	Eff: 87 FWHM: 16 Cd/lm: 6.41		View
 LUMILEDS LUXEON C Lime	Eff: 83 FWHM: 15 Cd/lm: 8.8		View
 LUMILEDS LUXEON C White	Eff: 83.3 FWHM: 12 Cd/lm: 15.8		View
 LUMILEDS LUXEON CSP 10 White	Eff: 88 FWHM: 16 Cd/lm: 3.67		View
 LUMILEDS LUXEON CZ	Eff: 90 FWHM: 11 Cd/lm: 19.3		View
 LUMILEDS LUXEON IR Compact 850nm	Eff: 91 FWHM: 14 Cd/lm: 11.1		View
 LUMILEDS LUXEON IR Domed 150 Degree	Eff: 89 FWHM: 17 Cd/lm: 7.9		View
 LUMILEDS LUXEON MZ White	Eff: 88 FWHM: 31 Cd/lm: 1.72		View
 LUMILEDS LUXEON Q White	Eff: 84.6 FWHM: 20 Cd/lm: 4.4		View

 
 
Manu.	Performance Data	Images	IES/STP
 LUMILEDS LUXEON R White	Eff: 86.2 FWHM: 25 Cd/lm: 4.9		View
 LUMILEDS LUXEON Rebel ES White	Eff: 86.2 FWHM: 25 Cd/lm: 4.9		View
 LUMILEDS LUXEON Rebel White	Eff: 84.5 FWHM: 18 Cd/lm: 9.7		View
 LUMILEDS LUXEON T White	Eff: 86.2 FWHM: 25 Cd/lm: 4.9		View
 LUMILEDS LUXEON TX White	Eff: 86.2 FWHM: 22 Cd/lm: 4.7		View
 LUMILEDS LUXEON Z ES White	Eff: 89 FWHM: 16 Cd/lm: 8.3		View
 LUMILEDS LUXEON Z White	Eff: 87 FWHM: 12 Cd/lm: 14.47		View
 Luminus Devices SST 10-B-B130 Blue	Eff: 90 FWHM: 18 Cd/lm: 9.5		View
 Luminus Devices SST 10-B-B90 Blue	Eff: 89 FWHM: 19 Cd/lm: 8.1		View
 Luminus Devices SST 10-DR-B90 Deep Red	Eff: 90 FWHM: 21 Cd/lm: 7.7		View

Manu.	Performance Data	Images	IES/STP
 Luminus Devices SST 10-G-B130 Green	Eff: 91 FWHM: 18 Cd/lm: 9.7		View
 Luminus Devices SST 10-G-B90 Green	Eff: 90 FWHM: 20 Cd/lm: 8		View
 Nichia 219 White	FWHM: 24 Cd/lm: 5.1		View
 Nichia 757 White	Eff: 88 FWHM: 18 Cd/lm: 4.11		View
 Nichia 757G White	Eff: 90.5 FWHM: 20 Cd/lm: 4.5		View
 Nichia NCSW E17A White	Eff: 87 FWHM: 21 Cd/lm: 4.16		View
 Nichia NF2W 385AR-V2 White	Eff: 90 FWHM: 25 Cd/lm: 3.8		View
 Nichia NVSL 219B White	Eff: 88.5 FWHM: 18 Cd/lm: 6.4		View
 Nichia NVSW 219C White	Eff: 89 FWHM: 26 Cd/lm: 3.5		View
 Nichia NVSW 319A White	Eff: 88 FWHM: 29 Cd/lm: 2.7		View

Manu.	Performance Data	Images	IES/STP
 Nichia NVSW E21A White	Eff: 87 FWHM: 20 Cd/lm: 4.16		View
 Nichia Top Emitting NCSL 119-H3 White	Eff: 82.6 FWHM: 17 Cd/lm: 7.7		View
 Osram OS DURIS E 2835 Gen2	Eff: 91.5 FWHM: 16 Cd/lm: 7.2		View
 Osram OS DURIS E 2835 White	Eff: 90 FWHM: 19 Cd/lm: 6		View
 Osram OS DURIS E2 White	Eff: 88 FWHM: 15 x 12 Cd/lm: 10.73		View
 Osram OS DURIS E3 White	Eff: 89.1 FWHM: 9 Cd/lm: 14.86		View
 Osram OS DURIS S2 White	Eff: 92.7 FWHM: 14 Cd/lm: 7.4		View
 Osram OS DURIS S5 Deep Blue	Eff: 89.5 FWHM: 18 Cd/lm: 6.1		View
 Osram OS DURIS S5 Green	Eff: 90.5 FWHM: 17 Cd/lm: 6.5		View

Manu.	Performance Data	Images	IES/STP
OSRAM Opto Semiconductors Osram OS DURIS S5 Red	Eff: 91 FWHM: 16 Cd/lm: 7.8		View
OSRAM Opto Semiconductors Osram OS DURIS S5 White	Eff: 88 FWHM: 19 Cd/lm: 4.73		View
OSRAM Opto Semiconductors Osram OS OSLON Black SFH 4725S IR	Eff: 92.5 FWHM: 22 Cd/lm: 6		View
OSRAM Opto Semiconductors Osram OS OSLON Square Flat White	Eff: 90 FWHM: 15 Cd/lm: 9		View
OSRAM Opto Semiconductors Osram OS OSLON Square Gen 3 White	Eff: 86.8 FWHM: 20 Cd/lm: 5.2		View
OSRAM Opto Semiconductors Osram OS OSLON Square Gen 5 GW CSSRM3	Eff: 90.5 FWHM: 42 x 22 Cd/lm: 2.7		View
OSRAM Opto Semiconductors Osram OS OSLON Square White	Eff: 86 FWHM: 21 Cd/lm: 5.28		View
OSRAM Opto Semiconductors Osram OS OSLON SSL 150 degree White	Eff: 85.7 FWHM: 14 Cd/lm: 12.7		View
OSRAM Opto Semiconductors Osram OS OSLON SSL 80 degree White	Eff: 85.5 FWHM: 19 Cd/lm: 8.6		View
 Samsung 3535 LH351A White	FWHM: 22 Cd/lm: 6.3		View

Manu.	Performance Data	Images	IES/STP
 Samsung 3535 LH351B White	Eff: 86.7 FWHM: 25 Cd/lm: 3.73		View
 Samsung 3535 LH351Z White	Eff: 86.5 FWHM: 21 Cd/lm: 5.91		View
 Samsung CSP LH181B White	Eff: 92 FWHM: 20.5 Cd/lm: 4.9		View
 Samsung CSP LM101B White	Eff: 92 FWHM: 18 Cd/lm: 6.7		View
 Seoul MidPower MJT3030 White	Eff: 87 FWHM: 16 Cd/lm: 6		View
 Seoul SunLike STW9 C2SB-S	Eff: 91.5 FWHM: 18 Cd/lm: 6.4		View
 Seoul Z - Power Z5 M1 White	Eff: 87 FWHM: 22 Cd/lm: 4.6		View
 Seoul Z - Power Z5M White	FWHM: 22 Cd/lm: 6		View
 SSC Z - Power Z5 White	Eff: 84.8 FWHM: 16 Cd/lm: 12.8		View
 SSC Z - Power Z5P White	FWHM: 18 Cd/lm: 8.4		View

Manu.	Performance Data	Images	IES/STP
TOSHIBA Toshiba TL 1L2 White	Eff: 85 FWHM: 23 Cd/lm: 4.35	 	View
TOSHIBA Toshiba TL 1L4 White	Eff: 86 FWHM: 22 Cd/lm: 4.2	 	View



[About us](#)
[Warranty](#)
[Terminology](#)
[GDPR](#)

[Carclo plc](#)
[Privacy](#)
[Terms of website use](#)

[General Instructions](#)
[Quality](#)
[Legislation](#)