
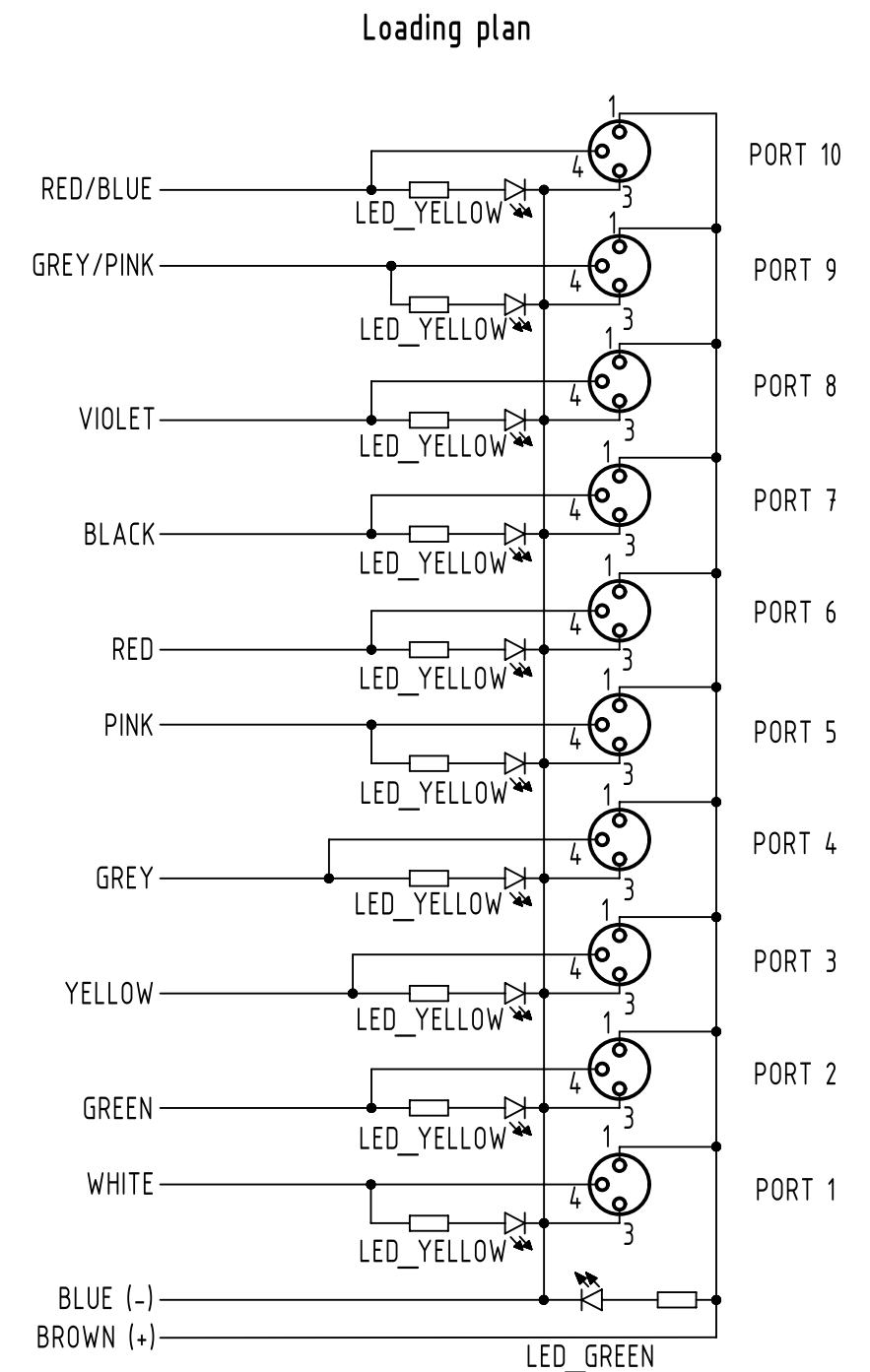


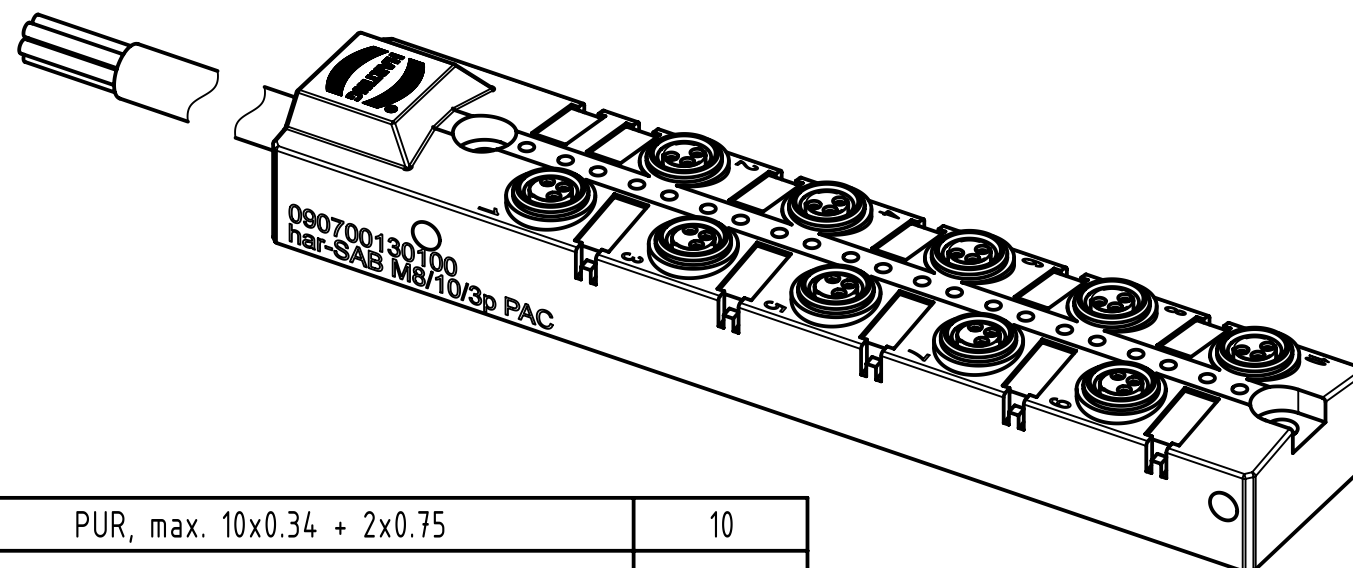

Electrical data:

- Rated voltage: 15-30V DC
- Nominal: 2 A per Contact
- Current: 6 A max total
- Protection level: IP 67
- Temperature range: -25°C...+80°C

PUR, max. 10x0.34 + 2x0.75	10
Type of cable	Dim. a[m]

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
		All rights reserved		Created by MUNTEANV		Inspected by POPESCU		Standardisation AVRAM	
Department HCS - RO		Title har-SAB M8/10/3p PAC		Date 2017-04-24		State Final Release		Doc-Key / ECM-Nr. 100689683/UGD/000/D 500000118447	
HARTING Customised Solutions D-32427 Minden		Type TB		Number 090700130100		Rev. D		Page 1/1	