
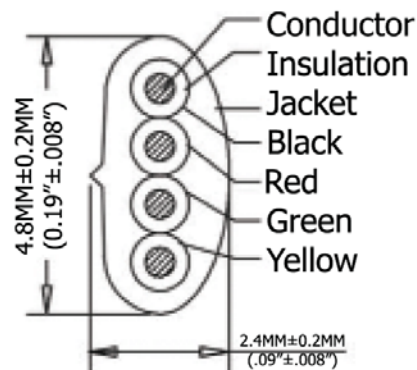


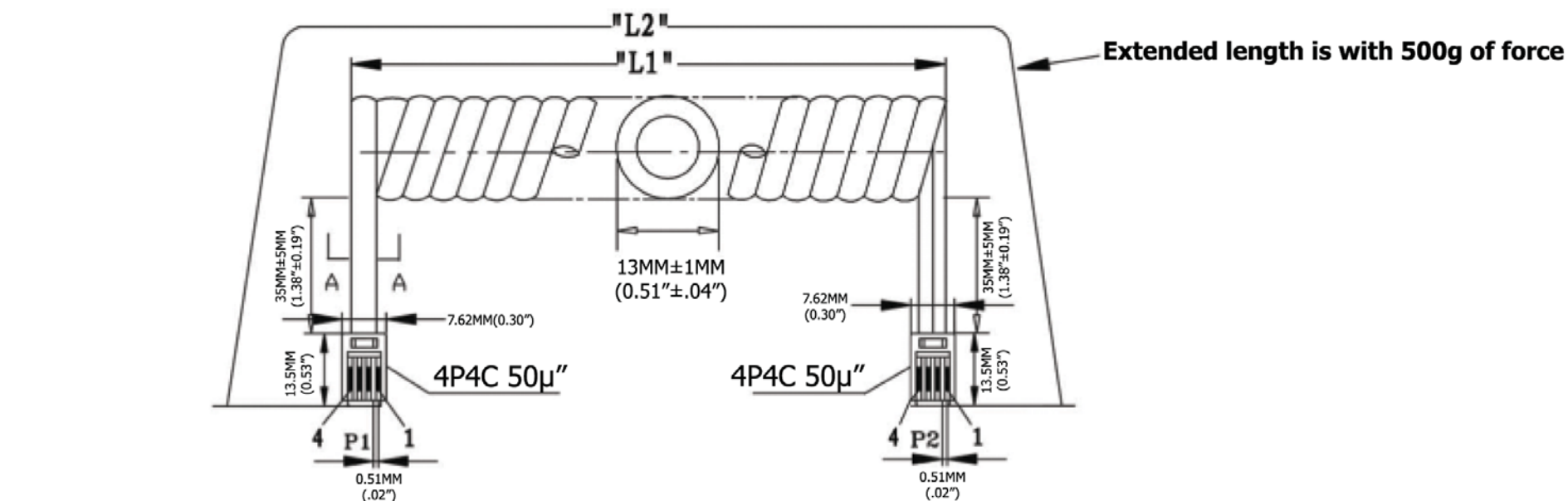

TERMINATION:

P1	P2	COLOR
1	1	BLACK
2	2	RED
3	3	GREEN
4	4	YELLOW

Material:

- Plug Housing: Polycarbonate, clear
- Plug Terminal: 0.36"[0.14MM] Thick Phosphor Bronze
- Connector: 50μ" of Selective Gold Contact Plating
 - Area, Gold flash over the remainder
 - Over 2.54μm[.000100] thick nickel underplate
- Conductor(X4C): 26AWG (0.12X12) Bare Copper
- Insulation(X4C): PP6331 ID 0.95-1.0
- Jack: PVC No UL 80 P
- Package: Individual PE Bag

Extended Length ("L2")	Typical Retracted Length ("L1")
168.0 Inches - 193.2 Inches	33.5 Inches
4,267.2MM-4,907.28MM	850.9MM

SEC:A-A

[illegible]

Item No.	
----------	--

AT-C-26-4/4/S-14/R

	Title
--	-------

NON-UL 26 AWG (0.12X12)*4C, O.D.: 2.4*4.8MM,
Standard Plug, 50μ" of contact plating, SILVER

Drawing No.

rev00

Replace

Sheet

RoHS
Complaint



ASSMANN
WSV components