

GRM31A5C2H181JW01#



“#” indicates a package specification code.



< List of part numbers with package codes >

GRM31A5C2H181JW01J GRM31A5C2H181JW01D

Appearance & Shape

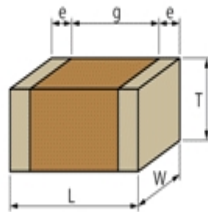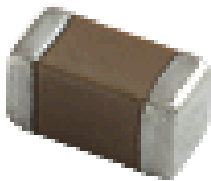

References

Packaging	Specifications	Standard Packing Quantity
J	330mm Paper Tape	10000
D	180mm Paper Tape	4000

Mass (typ.)	
1 piece	27.0mg

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

GRM31A5C2H181JW01#

“#” indicates a package specification code.



Specifications

Length	3.2±0.2mm
Width	1.6±0.2mm
Thickness	1.0+0/-0.3mm
Capacitance	180pF ±5%
Distance between external terminals g	1.5mm min.
External terminal size e	0.3mm min.
Operating Temperature Range	-55°C to 125°C
Rated Voltage	500Vdc
Size code in inch(mm)	1206 (3216M)
TC	0±30ppm/°C
Temperature characteristics (complied standard)	C0G(EIA)
Temperature range of temperature characteristics	25°C to 125°C

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.