


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	TLY-13	NEMA 5-15P	1	PVC, black
2	TLY-18	C13 female	1	PVC, black
3	30-01362	Wire, 3C, 14 AWG, UL SJT, 300V, 105C, 9.25 mm, VW-1, PVC	1	
4	Ac label	White with black text: "15A 125V AC"	1	

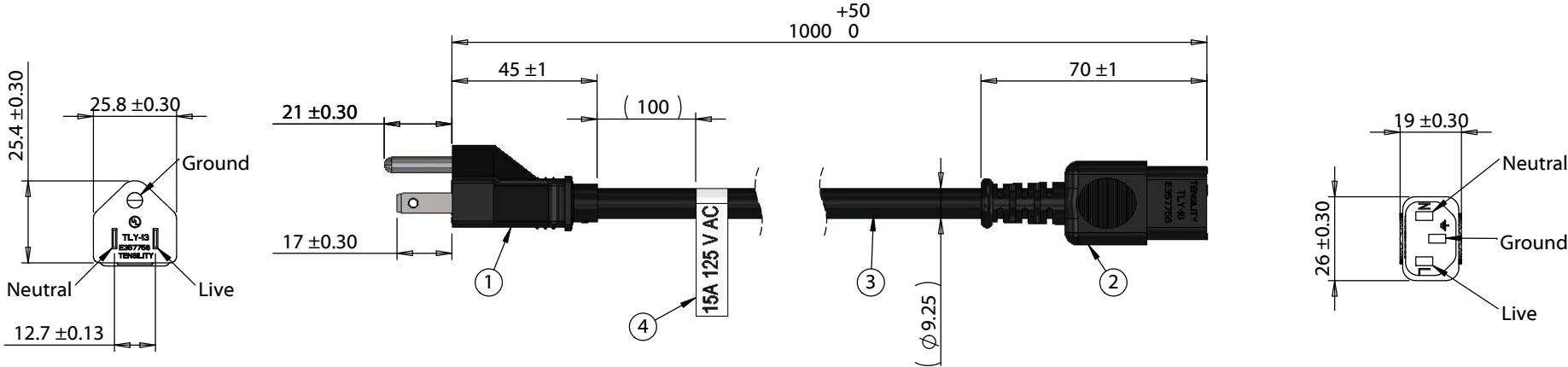

Notes:
Cable rated for 15 A, 125 Vac

Wiring Diagram		
TLY-13	wire color	TLY-18
Live	black	Live
Neutral	white	Neutral
Ground	green	Ground

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com		
A	5/19/2020	Initial release	Verified:				
			Dimensions are in millimeters.	Description:	Size:	Part number:	
			Tolerances:				
			X: ± 0.5 mm	Ac cord, 1000 mm, U.S., Nema 5-15P plug, TLY-13 to C13, 14 AWG, SJT wire, 30-01363	A	11-00126	
			X.X: ± 0.3 mm				
			X.XX: ± 0.05 mm		Scale:	1:2	Sheet 1 of 1

To see a custom version of this cable assembly, call Tensility at 541-323-3228 or email engineering@tensility.com