



TOP VIEW

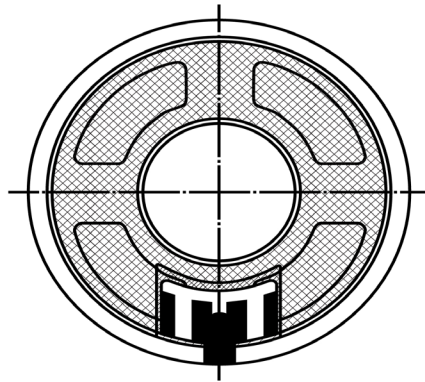

SIDE VIEW

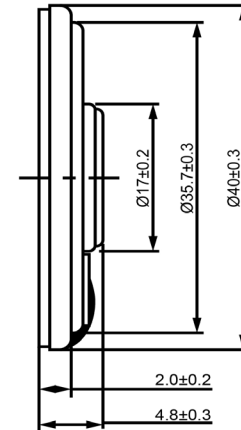

Specifications

Description	Value	Unit
Shape	Round	
Resonant Frequency	400	(Hz)
Frequency Range	400 ~ 4,500	(Hz)
SPL @ 10cm	95	(dBA)
Impedance	64	(Ohm)
Cone Material	Mylar	
Nominal Power	0.25	(W)
Max Power	0.4	(W)
Mount Type	Flush Mount	
Operating Temperature	-40 ~ +66	°C
Storage Temperature	-40 ~ +66	°C
Weight	9	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Dynamic Speaker

Revision History

Version	Description			Date	Approved
1	Released from Engineering			J.S.	5-Feb

SM400464-1