


Specification Sheet

Part Number: 151-00932

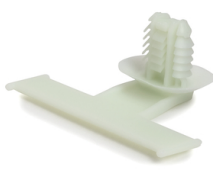

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 1.97" Long, 0.02 - 0.27" Panel Thickness, PA66HIRHS, Natural, 3000/carton

Article Number	151-00932
Type	SOC11FTOVAL
Color	Natural (NA)
Quantity Per	pack
Product Description	Standoff bundling clips provide a straightforward way to secure cable bundles, hoses or pipes. The bundle fastens to the tape bar using tape or cable ties. Multiple orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standoff keeps bundles away from mounting area to prevent them from damage due to rubbing.
Short Description	Standoff Bundling Clip, 1.97" Long, 0.02 - 0.27" Panel Thickness, PA66HIRHS, Natural, 3000/carton

Global Part Name	SOC11FTOVAL-PA66HIRHS-NA
Length L (Imperial)	1.97
Length L (Metric)	50.0
Offset Length (Imperial)	0.79
Offset Length (Metric)	20.0
Fixation Method	Fir Tree for oval holes
Width W (Imperial)	0.37
Width W (Metric)	9.5
Height H (Imperial)	0.79
Height H (Metric)	20.1
Panel Thickness Min (Imperial)	0.02
Panel Thickness Max (Imperial)	0.27
Panel Thickness Min (Metric)	0.6
Panel Thickness Max (Metric)	6.75
Mounting Hole Diameter D (Imperial)	0.27 x 0.47 " 0.24 x 0.48 " 0.25 x 0.50 "
Mounting Hole Diameter D (Metric)	6.2 x 12.2 mm 6.5 x 13.0 mm 6.5 x 12.5 mm 7.0 x 12.0 mm

Mounting Hole Diameter D Min (Imperial)	0.24
Mounting Hole Diameter D Max (Imperial)	0.50
Mounting Hole Diameter D Max (Metric)	13.0
Material	Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)
Material Shortcut	PA66HIRHS
Flammability	UL 94 HB
Halogen Free	Yes
UV Resistant (Yes/No)	No
Operating Temperature	-40°F to +221°F (-40°C to +105°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes
Package Quantity (Imperial)	3000
Package Quantity (Metric)	3000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2025 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Disclaimer](#) [Terms and Conditions](#)