


Pressure screw - HC-DS-PG16-Z - 1772638

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

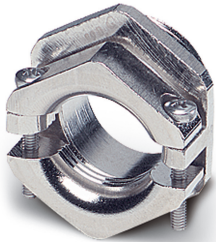

Pressure screws, with strain relief clamps, nickel-plated brass, clamping range 11 mm ... 15 mm, type Pg16

RoHS

Key Commercial Data

Packing unit	1 pc
Minimum order quantity	10 pc
GTIN	 4 017918 037291
GTIN	4017918037291
Weight per Piece (excluding packing)	37.930 g
Custom tariff number	74199990
Country of origin	Germany

Technical data

Dimensions

Wrench size, union nut	27 mm
Clamping range of the strain relief clip	11.00 mm ... 15.00 mm

General

Material, pressure screw	Nickel-plated brass
--------------------------	---------------------


Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Pressure screw - HC-DS-PG16-Z - 1772638

Drawings

Dimensional drawing

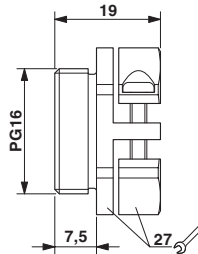

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	27144432
eCl@ss 4.0	27141200
eCl@ss 4.1	27141200
eCl@ss 5.0	27149100
eCl@ss 5.1	27149100
eCl@ss 6.0	27149100
eCl@ss 7.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 2.0	EC000441
ETIM 3.0	EC000441
ETIM 4.0	EC000441
ETIM 6.0	EC000441
ETIM 7.0	EC000441

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121311
UNSPSC 18.0	39121311
UNSPSC 19.0	39121311
UNSPSC 20.0	39121311



Pressure screw - HC-DS-PG16-Z - 1772638

Classifications

UNSPSC

UNSPSC 21.0	39121311
-------------	----------