


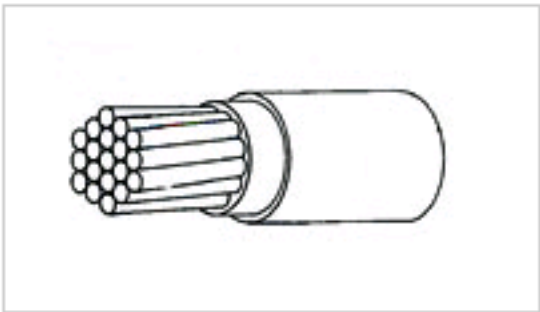





44A0111-24-0-MX Product Details

 [Share](#)  [Print](#)  [Email](#)



 **Active**

Spec 44, Spec 55 and Spec RCW Wire and Cable

44A0111-24-0
44A0111-24-0-MX 
TE Internal Number: 282040-015

[Product Highlights](#) [View All](#)




- Cable Type = Spec 44
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC




- [Pricing & Availability](#) 
- [Request Sample](#) 
- [Add to My Part List](#) 
- [Buy Product through Distributor](#) 

 Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
Use the Product Drawing for all design activity

| Product Type Features | |
|---|--|
| Cable Type  | Spec 44 |
| Cable Style  | Primary |
| Electrical Characteristics | |
| Voltage Rating (VAC) | 600 |
| Dimensions | |
| Conductor Outer Diameter (mm [in]) | 0.64 [0.025]  |
| Body Features | |
| Wire Size (AWG/CM) | 24 AWG |
| Conductor Type | Tin-Coated Copper |
| Wire Color | Black |
| Nominal Outside Diameter (mm [in]) | 1.02 [0.040] |
| Wire Diameter (mm [in]) | 1.02 [0.040] |
| Configuration Features | |
| Number of Conductors | 1 |

| Industry Standards | |
|--|--|
| Government/Industry Qualification | No |
| RoHS/ELV Compliance  | RoHS compliant, ELV compliant |
| Lead Free Solder Processes  | Not relevant for lead free process |
| RoHS/ELV Compliance History | Always was RoHS compliant |
| Conditions for Usage | |
| Temperature Range (°C) | -65 – +150  |
| Wire Size - Details | 24 AWG 0.24 mm ² , 0.00037 in ² , 19 x 36 AWG |
| Operation/Application | |
| Application | General Purpose - Light Weight |
| Packaging Features | |
| Wire Source | United States |
| Other | |
| Brand | Raychem |
| Node Classification | Hook Up Wire |

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information
[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)

Quick Links
[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support
[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

