


CONSTANT CURRENT LED DRIVERS

DAL SERIES

50 & 30 W CLASS 2 / CLASS II CC LED DRIVER WITH DALI DIMMING

Input Voltage	Max Output Power	Output Current Range
120 to 277 Vac	50 W	300 to 1200 mA Constant Current

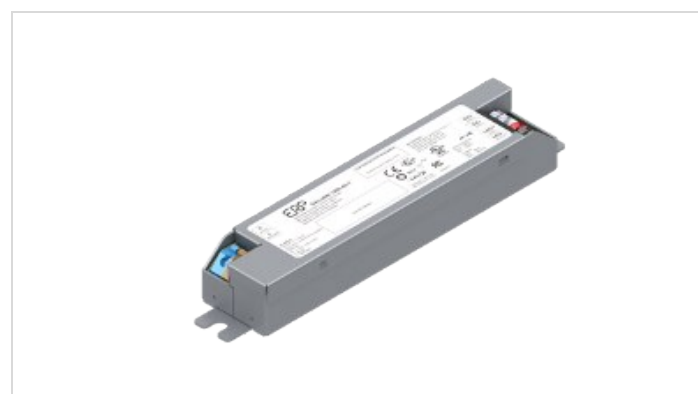

FEATURES:

- ▶ Universal input voltage range
- ▶ Ripple < 10% @ 20% & 100% load
- ▶ Turn-on @ 1% Iout
- ▶ EMI: Compliant with FCC CFR Title 47 Part 15 Class B at 120 Vac & Class A at 277 Vac and with CE EN55015 (CISPR 15) at 220, 230, & 240 Vac

PROGRAMMING

[+ VIEW ALL FEATURES](#)

APPLICATIONS:

- Architectural
- Commercial lighting
- Indoor lighting
- Residential light



SELV



TECHNICAL DOCUMENTATION:

> DATASHEET

EMAIL ME THE ADDITIONAL DOCUMENTATION:

- ☐ CAD File
- ☐ Safety Agency Approval
- ☐ Dimmer Compatibility

SUBMIT

ERP Part Number	Status	Availability
DAL50W-1200-42-T	production	Check >
DAL50W-0850-56-T	production	Check >
DAL30W-0600-42-T	production	Check >

NOTES:

There are currently no notes available at this time.

RELATED ACCESSORIES

 [View All](#)



OUR DISTRIBUTORS

TECHNICAL DOCUMENTATION

+ 1-805-517-1300

ABOUT US

Who We Are
Leadership
Careers

NEWS & EVENTS

Latest News
Upcoming Events

CONTACT US

Locations
Order a Sample

© 2021 ERP Power LLC. – All Rights Reserved – Light Engine Warranty | Driver
Warranty | Terms & Conditions | Privacy Policy | Site Map
Website by: fishnet

Privacy & Cookies Policy