


2129571-2 Product Details

 Share  Print  Email

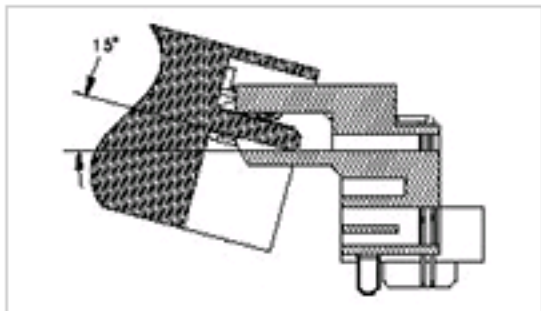

 Active

 View 3D PDF

Serial ATA & Serial Attached SCSI

REC. ASSY, Slant Insertion SATA, H7.85

2129571-2
TE Internal Number: 2129571-2

Product Highlights [View All](#)

- Connector
- Without Shell
- Receptacle
- 22 Positions
- Number of Rows = Single

Pricing & Availability

Request Sample

Add to My Part List

Buy Product through Distributor

Feedback

Documents

Features

Compliance

Please Note:
Use the Product Drawing for all design activity

Product Type Features	
Product Type ?	Connector
Connector Type ?	Receptacle
PCB Mounting Orientation ?	Right Angle
Receptacle Configuration	SATA
PCB Mount Style ?	Straddle Mount
PCB Mount Retention ?	Without
Keyed	No

Dimensions	
PCB Thickness, Recommended (mm [in])	1.00 [0.039]

Body Features	
Mount Type	Printed Circuit Board

Contact Features	
Contact Base Material	Copper Alloy
Contact Plating, Mating Area, Material ?	Gold
Solder Tail Contact Plating	Matte Tin

Housing Features	
Housing Material	High Temperature Thermoplastic
Housing Color	Black
Mating Alignment Type	Polarization

Configuration Features	
Shell	Without
Number of Positions ?	22
Number of Rows ?	Single
Number of Ports	2
Stackable	No

Industry Standards	
RoHS/ELV Compliance ?	Not reviewed for ELV/RoHS compliance
Lead Free Solder Processes ?	Not reviewed for lead free solder process
UL Flammability Rating	UL 94V-0

Conditions for Usage	
High Temperature Housing ?	Yes

Packaging Features	
Packaging Method	Tape & Reel
Packaging Quantity	250

Other	
Brand	TE Connectivity
Comment	Slant insertion.
Node Classification	SATA Connectors

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)