

Product Searches


- 7/16
- 1.0/2.3
- 1.6/5.6
- AFI
- AMC
- BNC / RP-BNC
- C
- FAKRA SMB
- FME
- HN
- MCX
- Mini-UHF
- Mini 75 ? SMB
- MMCX
- Precision (APC)
- QMA
- SC
- SlimLine BNC
- SMA / RP-SMA
- SMB
- SMC
- SMP
- SSMB
- TNC / RP-TNC
- Triax
- True 75 ? BNC
- Tw in BNC
- Tw inax
- Type F
- Type G
- Type N
- UHF
- Reverse Polarity

- Adapters
- Cable Assemblies
- Tools
- Accessories

Product Search

Inventory Search

product details

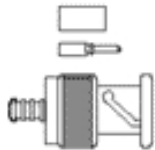

Please note: Images are for reference only

Amphenol Part Number:	031-5558-RFX
Product Series:	BNC
Product Type:	Connectors » Cable
Application:	Crimp
Body Plating:	Nickel
Body Termination:	Crimp
Cable Group:	G1
Cable Type:	89248, Belden 89248, Belden 9290, RG-212, RG-6
Connector Body Style:	Straight
Contact Plating:	Gold
Contact Termination:	Press Fit
Gender:	Plug
Grade:	Commercial
Impedance:	50 Ohm
RoHS Certificate:	Yes
More Information:	Assembly Instructions
	Customer Drawing
	Distributor Inventory