

Sealing frame - CES-B10-SFFS-PLBK - 0801660

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sealing frame with screw locking, size B10, with flat gasket, for 6 small sleeves

Product Description

Sealing frame with screw locking, including flat gasket, mounting screws not supplied as standard

RoHS

Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 674126
GTIN	4046356674126
Weight per Piece (excluding packing)	120.000 g
Custom tariff number	85472000
Country of origin	Poland

Technical data

Dimensions

Length	99.2 mm
Width	58 mm
Height	20 mm

Ambient conditions

Degree of protection	IP54 (Observe the assembly instructions)
	IP65 (Observe the assembly instructions)
Ambient temperature (operation)	-40 °C ... 120 °C (static)

General

Sealing frame - CES-B10-SFFS-PLBK - 0801660

Technical data

General


Product description	Sealing frame with screw locking, including flat gasket, mounting screws not supplied as standard
Frame type	Sealing frame
Material	PA (halogen-free)
Flammability rating according to UL 94	V0
Color	black
Torque	2 Nm ... 4 Nm (Locking screw)
Installation instructions	M4 locking screw with 3 mm Allen screw head, 2 ... 4 Nm torque, 1 large sleeve requires the space of 4 small sleeves, mounting screw: M4 (ISO 4762/DIN 912), 1.8 Nm torque
	The flat gasket supplied should be inserted between the wall and the sealing frame in the case of wall mounting. IP54: for vertical sealing frame mounting/for horizontal sealing frame mounting (downward cable outlet direction). IP65: when using the CES-SRC-BK / CES-LRC-BK cone sleeve, for vertical mounting/horizontal mounting (downward cable outlet direction) of the sealing frame directly on the housing panel, and use of a 3.6 mm wide cable binder (e.g., item 3240744).

Standards and Regulations


Connection in acc. with standard	CUL
Flammability rating according to UL 94	V0

Drawings

Dimensional drawing

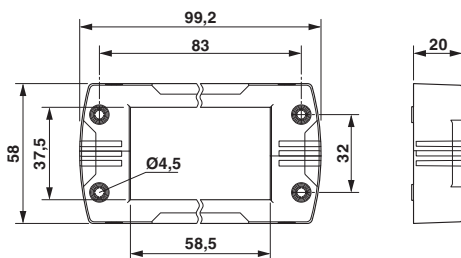

Dimensional drawing

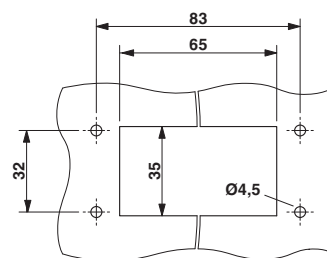

Dimensional drawing

Panel cutout

Classifications

eCl@ss

eCl@ss 4.0	23110102
eCl@ss 4.1	23110102
eCl@ss 5.0	23110102
eCl@ss 5.1	23110102

Sealing frame - CES-B10-SFFS-PLBK - 0801660

Classifications

eCl@ss

eCl@ss 6.0	23110102
eCl@ss 7.0	23110102
eCl@ss 8.0	27142421
eCl@ss 9.0	27142421

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC002498
ETIM 5.0	EC000211
ETIM 6.0	EC000211

UNSPSC

UNSPSC 6.01	27113201
UNSPSC 7.0901	27113201
UNSPSC 11	27113201
UNSPSC 12.01	27113201
UNSPSC 13.2	27113201

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / GL / cULus Recognized

Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	NITW2.E255026
---------------	---	---	---------------

cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	NITW8.E255026
----------------	---	---	---------------

Sealing frame - CES-B10-SFFS-PLBK - 0801660

Approvals

GL



<http://exchange.dnv.com/tari/>

1391415 HH

cULus Recognized



<http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm>

Accessories

Accessories

Mounting material

Screw - CES-SFFS-H - 0801728



M4 replacement screw with 4 mm Allen screw head for sealing frame with screw locking

Screwdriver tools

Screwdriver - SF-M BH - 1212070



Bit screwdriver, with 1/4" quick-action chuck, handle length 119 mm, 2-component handle, with non-slip grip, suitable for bits according to DIN 3126-C 6.3 and E 6.3/ISO 1173, magnetic

Screwdriver - SF-BIT-HEX 3-50 - 1212647



Screw bit, hexagon, E6.3-1/4" drive, size: Hex 3 x 50 mm, hardened, suitable for holder according to DIN 3126-F6.3/ISO 1173

Seal

Sealing frame - CES-B10-SFFS-PLBK - 0801660

Accessories

Flat gasket - CES-B10-WRG-BK - 0801725



Flat gasket made of NBR, size B10

Phoenix Contact 2017 © - all rights reserved
<http://www.phoenixcontact.com>