


Product Status	Production
Applications	Commercial Grade
Feature	High Speed High speed signal line
Series	MMZ
Brand	TDK
Environmental Compliance	 RoHS  REACH  Halogen Free  Lead Free

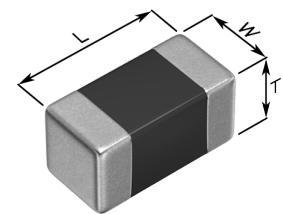



Size	
Length(L)	0.60mm $\pm 0.03\text{mm}$
Width(W)	0.30mm $\pm 0.03\text{mm}$
Thickness(T)	0.30mm $\pm 0.03\text{mm}$
Recommended Land Pattern (A)	0.25mm Nom.
Recommended Land Pattern (B)	0.30mm Nom.
Recommended Land Pattern (C)	0.30mm Nom.

Electrical Characteristics	
Impedance at 100MHz	56 $\Omega$ $\pm 25\%$
Rated Current	100mA
DC Resistance (Max.)	950m $\Omega$

Other	
Operating Temp. Range (Including Self-Temp. Rise)	-55 to 125°C
Soldering Method	Reflow Iron Soldering
AEC-Q200	NO
Packing	Punched (Paper)Taping [180mm Reel, Tape width 8mm]
Package Quantity	15000pcs
Weight	0.0003g


! Images are for reference only and show exemplary products.  
 ! This PDF document was created based on the data listed on the TDK Corporation website.  
 ! All specifications are subject to change without notice.

## Characteristic Graphs (This is reference data, and does not guarantee the products characteristics.)

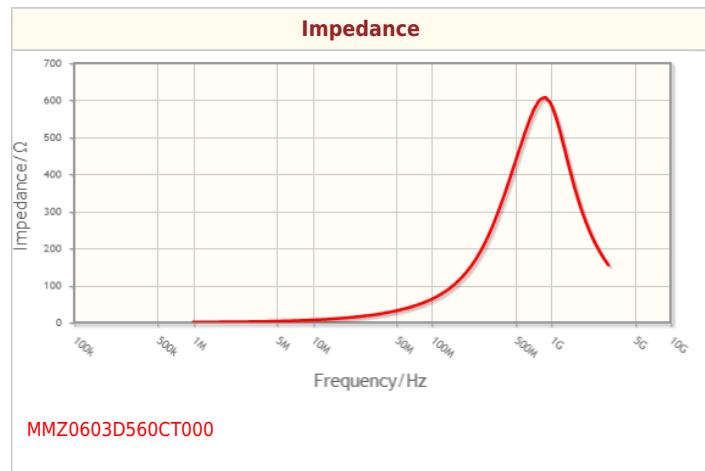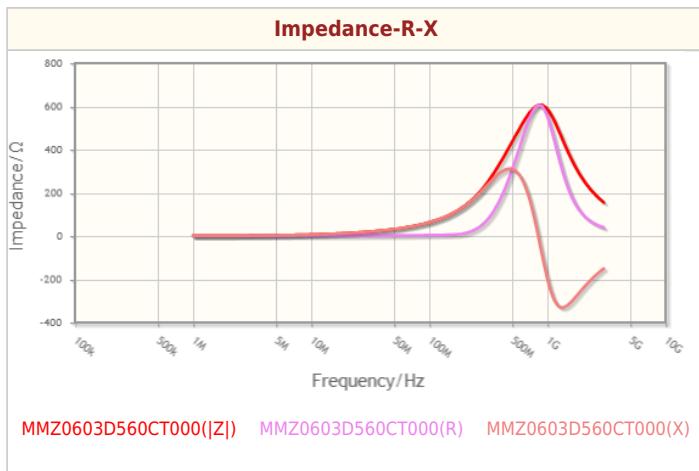

! Images are for reference only and show exemplary products.  
! This PDF document was created based on the data listed on the TDK Corporation website.  
! All specifications are subject to change without notice.

## Associated Images

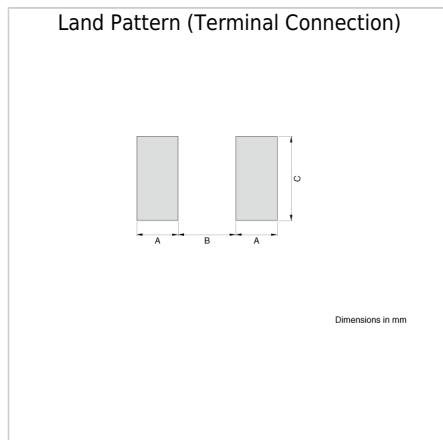

! Images are for reference only and show exemplary products.  
! This PDF document was created based on the data listed on the TDK Corporation website.  
! All specifications are subject to change without notice.