

Ferrule - AI 0,25- 6 BU - 3201291

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Ferrule, sleeve length: 6 mm, length: 10.5 mm, color: blue

The figure shows the version AI
0.75-8 BU

RoHS

Key Commercial Data

Packing unit	1 pc
GTIN	 4 017918 094799
GTIN	4017918094799
Weight per Piece (excluding packing)	0.070 g
Custom tariff number	74152900
Country of origin	Germany

Technical data

Dimensions

Length (b)	10.5 mm
Maximum stripping length	8 mm
Sleeve length	6 mm
Inner dimension of the insulating collar (d)	2 mm
Ferrule diameter	0.8 mm
Insulating collar thickness	0.25 mm
Sleeve wall thickness	0.25 mm

Ambient conditions

Short-term temperature	120 °C
------------------------	--------

Ferrule - Al 0,25- 6 BU - 3201291

Technical data

Ambient conditions


Max. permanent temperature	105 °C (-40°C no load / 0°C dynamic load)
----------------------------	---

General

Color	blue
Components	free from silicone and halogen
Material	CU-DHP
Coating	tin-plated (galvanic)

Drawings

Dimensional drawing

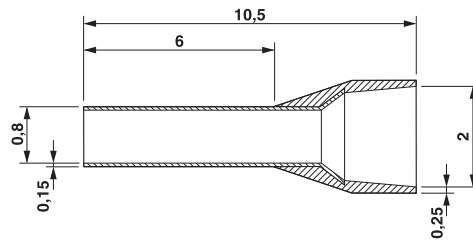

Classifications

eCl@ss

eCl@ss 4.0	27060701
eCl@ss 4.1	27060701
eCl@ss 5.0	27400201
eCl@ss 5.1	27400201
eCl@ss 6.0	27400201

ETIM

ETIM 2.0	EC000005
ETIM 3.0	EC000005
ETIM 4.0	EC000005

UNSPSC

UNSPSC 7.0901	27121703
UNSPSC 11	27121703
UNSPSC 13.2	27121703

