




Part Number : [2058264084](#)
Product Description : ConnTAK50 Tang
Receptacle with CPA, Dual Row, 10 Circuits / 8
Circuits Usable, Key D, Violet
Series Number : 205826
Status : Active
Product Category : Connector Housings

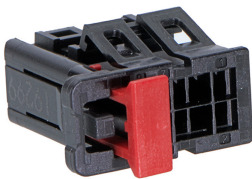

Documents & Resources

Drawings
[2058264084_sd.pdf](#)
[PK-31301-695-001.pdf](#)

3D Models and Design Files
[2058264084_stp.zip](#)

Specifications
[2046310000-PS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	205826
Description	ConnTAK50 Tang Receptacle with CPA, Dual Row, 10 Circuits / 8 Circuits Usable, Key D, Violet
Application	Automotive, Power, Signal, Wire-to-Board
Product Name	ConnTAK50
UPC	191128810777

Physical

Circuits (maximum)	8
Color - Resin	Violet
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.172/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.80mm
Pitch - Termination Interface	1.80mm
Polarization	D
Polarized to Mating Part	Yes
Stackable	No

Temperature Range - Operating	-40° to +100°C USCAR Class T2, -40° to +105°C LV-214
-------------------------------	--

Mates With / Use With

Mates with Part(s)

Description	Part Number
ConnTAK50 Right-Angle, Dual Row, Surface Mount Headers	<u>206958</u>
ConnTAK50 Vertical, Dual Row, Surface Mount Headers	<u>206957</u>

Use with Part(s)

Description	Part Number
TAK50 Receptacle Terminal, Unsealed, L-Grip, D-Wind, Left Reel Payoff	<u>2000963101</u>
TAK50 Receptacle Terminal, Unsealed, L-Grip, B-Wind, Right Reel Payoff	<u>2000963161</u>
TAK50 Receptacle Terminal, Unsealed, S-Grip, D-Wind, Left Reel Payoff	<u>2000963201</u>
TAK50 Receptacle Terminal, Unsealed, S-Grip, B-Wind, Right Reel Payoff	<u>2000963261</u>

This document was generated on Apr 26, 2025