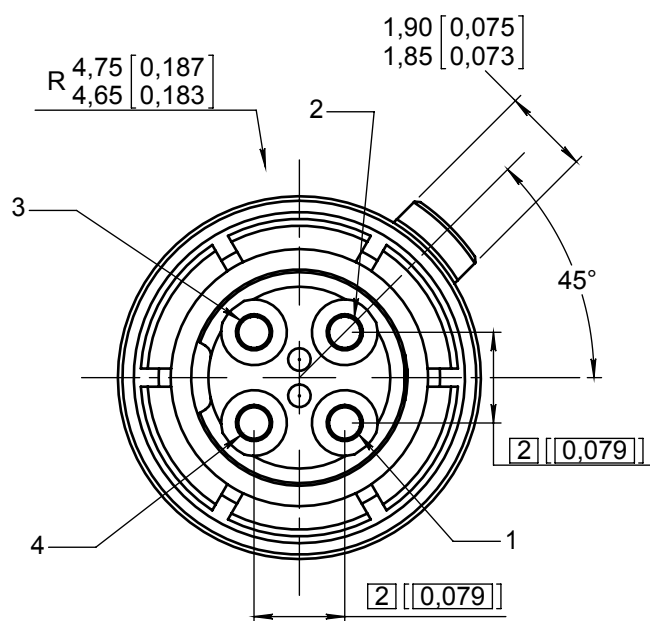
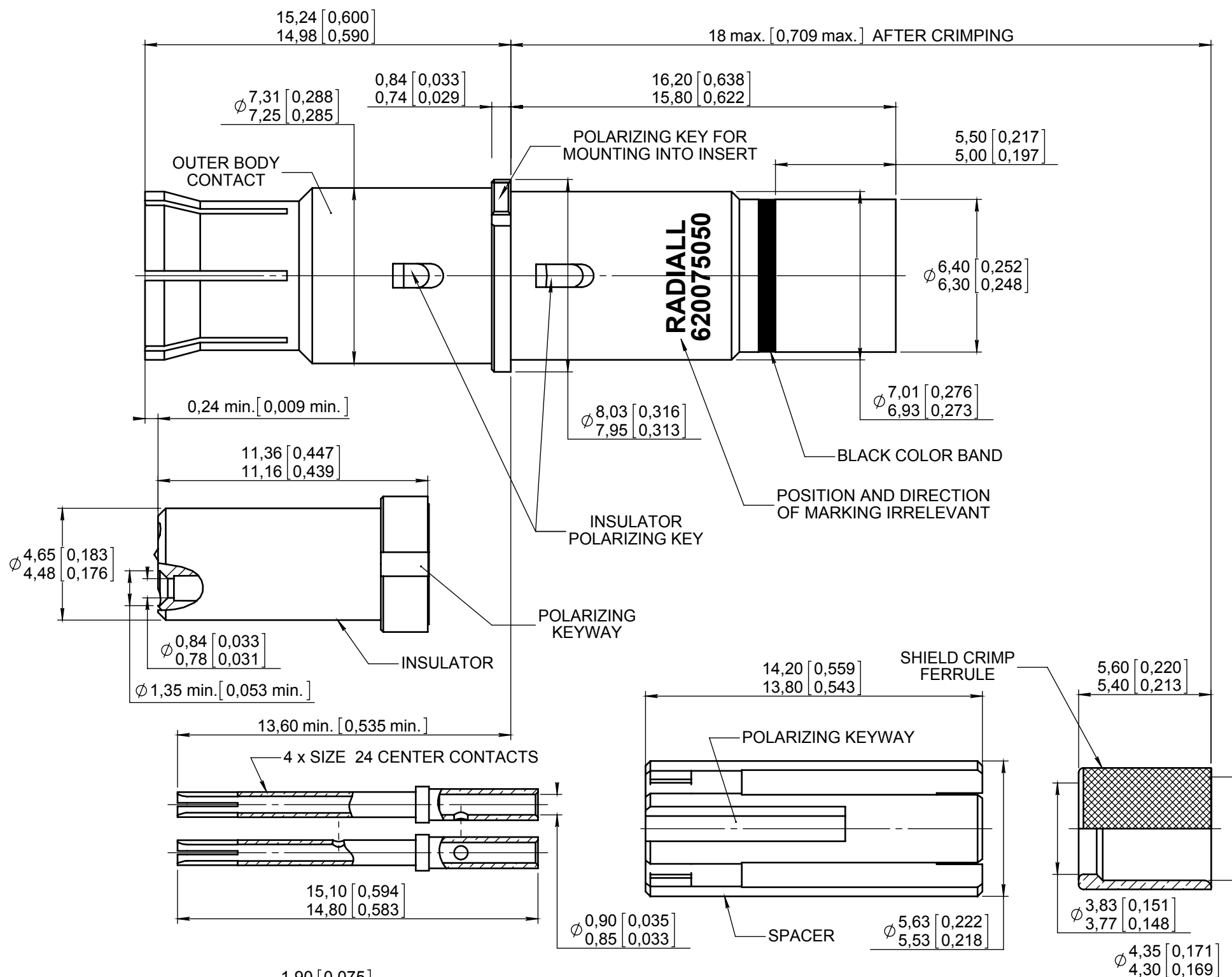


Series
NSXSIZE 8 QUADRAX SOCKET CONTACT
FOR QUADRAX TENSOLITE NF24Q100 (BMS13-72T03C04G024), ECS 422404
PIC E51424 AND THERMAX MX100Q24 CABLESIssue:
Nov. 02, 2015Page
1/1

ENGAGING FACE

MATERIAL:

- OUTER AND CENTER CONTACTS: COPPER ALLOY
- FERRULE: BRASS PER QQ-B-626
- INSULATOR : PTFE PER ASTM-D-1710 OR EQUIVALENT
- SPACER : THERMOPLASTIC PER ASTM D 5205

FINISH:

 
- ALL METAL PARTS:
PLATING .00005 INCH OF GOLD PER MIL-G-45204 TYPE I OR II
GRADE C OR D CLASS 1 OVER NICKEL PER QQ-N-290

EXTRACTION TOOL:

- M81969/28.03 (RADIAL: 282 549 001) OR M81969/14-06

WIRING INSTRUCTIONS: SEE RP57339.

DIMENSIONS : mm (inch are given for information only)



Estimated weight : 4.2 g

CREATION

PEN: M030400018E

NOM: LEGENDRE

DATE: NOV. 19, 2003

APPR.: LAHOREAU C.

Nov. 02, 15	Corrected spacer diameter	Branjonneau V.	Legendre T.
Sept. 04, 15	Add PIC E51424 cable	Pécault B.	Legendre T.
Sept. 05, 12	Updated way of marking	Legendre	Dupuis
Feb. 22, 12	Add BMS13-72T03C04G024 cable	Moutault	Dupuis
June 08, 09	Added ECS and Thermax cables	MACARI	LEGENDRE
July. 21, 05	Error corrected for spacer's material	LEGENDRE	LAHOREAU
Issue	Revisions	Name	Approved

620075050EN

RADIAL PROPRIETARY INFORMATION