

Part Number : [190090018](#)


Product Description : VibraKrimp Quick Disconnect Flag, Female, for 16-14 AWG Wire, Metal Strip Carrier

Series Number : 19009

Status : Active

Product Category : Quick Disconnects

Engineering Part Number : BBZ-4171-032

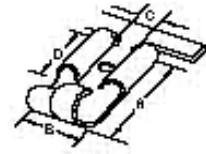

Documents and Resources

Drawings

[190090018_sd.pdf](#)


[PK-19009-001-001.pdf](#)

Specifications

[PS-19902-005-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)6375-DC (05 Nov 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration

- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Quick Disconnects
Series	19009
Description	VibraKrimp Quick Disconnect Flag, Female, for 16-14 AWG Wire, Metal Strip Carrier
Comments	Wire Grip
Product Name	VibraKrimp
Type	Flag Terminal
UPC	800755046939

Agency

CSA	LR18689
UL	E79133

Electrical

Voltage - Maximum	Per Wire Specification
-------------------	------------------------

Physical

Barrel Type	Closed
Gender	Female
Glow-Wire Capable	No
Insulated	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin

Material - Plating Termination	Tin
Net Weight	0.679/g
Orientation	Flag
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Polarized to Mating Part	No
Tab Thickness	0.81mm
Tab Width	4.75mm
Temperature Range - Operating	Per Wire Specification
Wire Insulation Diameter	3.68mm
Wire Size (AWG)	14, 16
Wire Size mm ²	1.30-2.00

Application Tooling

Global

Description	Part Number
Mini-Mac Applicator Rear Feed	<u>638027700</u>

This document was generated on Dec 18, 2025