


## GP6426, Mech Ground Conn, 2 Cables to Rod or Pipe

By Burndy  
Catalog # [GP6426](#)

Mechanical Grounding Connector, 2 Cables to Rod or Pipe, 4 AWG (Sol.) - 2/0 AWG (Str.), 3/8" Pipe, 5/8" - 3/4" Rod, 3/8" Stud

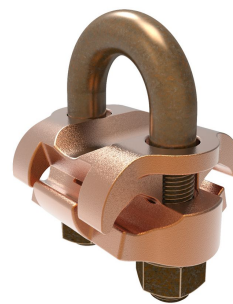

### Features

- Rated for Direct Burial in earth or concrete
- UL467 Listed for the US and Canadian Markets
- One-wrench installation

### Application

For Joining A Range Of Parallel Copper Cables Perpendicular To Rod, Pipe Or Column, Direct Burial In Earth Or Concrete

### Specifications

|   |       |
|---|-------|
| Certification - UL Recognized           | No    |
| Buy American Compliant                  | No    |
| Certification - cULus                   | No    |
| EU RoHS Indicator                       | Yes   |
| Industry Standard(s)                    | UL467 |
| Certification - ETL                     | No    |
| Standards - Industry Standards Met      | UL467 |
| Standards - RoHS Compliance Status      | EX    |
| Certification - UL Listed Direct Burial | Yes   |
| UL Listed                               | Yes   |
| Certification - CSA Approved            | No    |

### Conductor

|                                     |                          |
|-------------------------------------|--------------------------|
| Conductor - Rod Size Range          | 5/8 in - 3/4 in          |
| Conductor - Rod Size                | 1/2 in                   |
| Conductor Size                      | #4 AWG Sol - 2/0 AWG Str |
| Conductor - Copper Solid Size Range | 4-3/0                    |
| Conductor - Copper Str Size Range   | 5 AWG - 2/0 AWG          |

### Dimensions

|                       |          |
|-----------------------|----------|
| Package Height        | 0.000 in |
| Dimension - Height mm | 63.5 mm  |

|                                 |           |
|---------------------------------|-----------|
| Dimension - Height inch         | 2.50 in   |
| Dimension - Height fraction     | 2-1/2 in  |
| Package Weight                  | 0.000 lb. |
| Package Length                  | 0.000 in  |
| Package Width                   | 0.000 in  |
| Dimension - L Length Overall mm | 43 mm     |
| Dimension - Width fraction      | 2-1/8 in  |
| Bolt Size                       | 3/8 in    |
| Dimension - Width mm            | 54 mm     |
| Dimension - Width inch          | 2.12 in   |
| Dimension - B Length inch       | 1.50 in   |
| Dimension - Length Overall inch | 1.69 in   |

### Force Related

|                                       |            |
|---------------------------------------|------------|
| Installation Torque Recommended in-lb | 240 LBS/in |
|---------------------------------------|------------|

### General

|                              |                          |
|------------------------------|--------------------------|
| Material Type - Screw Plated | DURIUM™ Silicon Bronze N |
| Sub Brand                    | MECHANICAL CONNECTOR     |
| UPC                          | 781810260548             |
| Type                         | GP                       |
| U Bolt Type                  | 187                      |
| Material                     | Copper Alloy             |
| Plating Type                 | Unplated                 |
| UPC 14 Digit GTIN            | 00781810260548           |

### Logistics

|                       |      |
|-----------------------|------|
| Minimum Pack Quantity | 1    |
| Pallet Quantity       | 2880 |
| Carton Quantity       | 12   |

### Product Assets

[Catalog \[English\]](#)