 


Home → Tool Types → Torque Screwdrivers → Adjustable TorqueVario-S Newton Meter Handles

Quickly see and find recommended torque blades for this handle

Adjustable TorqueVario-S Newton Meter Handles



Zoom

Titles and descriptions supersede the photo. We typically use the same image for different sizes of tools.

Be the first to review this product

Filter:

SKU	Product	Range Nm	Nm Increments	Torque Accuracy	Price	Qty
28550	Adjustable Torque Vario-S 0.1-0.6Nm	0.1 - 0.6 Nm	0.02 Nm	±10%		0
28551	Adjustable Torque Vario-S 0.4-1.0Nm	0.4 - 1.0 Nm	0.05 Nm	±6%		0
28552	Adjustable Torque Vario-S 0.5-2.0Nm	0.5 - 2.0 Nm	0.10 Nm	±6%		0
28553	Adjustable Torque Vario-S 1.0-5.0Nm	1.0 - 5.0 Nm	0.20 Nm	±6%		0
28655	Adjustable Torque Vario-S 2.0-7.0Nm	2.0 - 7.0 Nm	0.25 Nm	±6%		0

Add to Cart

We accept



Frequently bought together



Price for all selected :

[Add selected to cart](#)

This item: [Adjustable TorqueVario-S Newton Meter Handles](#)

☒ [TorqueControl Bit Holder Adapter Blade For 1/4" Bits](#)

☒ [TorqueControl Square Drive Adapter Blade For 1/4" Sockets](#)

☒ [TorqueControl Adapter Blade For 4mm Bits](#)

Details

EN ISO 6789, BS EN 26789, ASME B107.14M

Tools Marked with Serial No. & Include Calibration Certificate

Ergonomic Multi-Component Handle, particularly light and compact

Handle sizes proportioned to optimize torque range

Audible and perceptible click when the pre-set torque has been attained

±6% Accuracy

Quality & Accuracy Guaranteed to 5000 Cycles or 1 year

Secure Torque Setting, come with torque adjustment tool

Loosening torque approx. +30% greater than tightening torque

Automatically resets for next torque cycle

Additional Info

Country of Manufacture	Germany
TorqueControl Type	Adjustable TorqueVario
Handle Grip Types	SoftFinish - cushioned
Torque Display Scale	Newton Meter

WRITE YOUR OWN REVIEW


Only registered users can write reviews. Please, [log in](#) or [register](#)

Warranty Info

Wiha Products Carry a **100% Satisfaction Guarantee**. All Wiha tools are guaranteed to be free of defects in workmanship and materials and will be replaced if found to be deficient providing tools have not been altered or misused. Wiha Insert Bits, Power Bits, Ceramic Tools and Tweezers are not warranted for use. Wiha Brand Torque control Tools are warranted for twelve months from date of purchase up to 5,000 torque Cycles.

[View Full Warranty](#)

You may also be interested in the following product(s)

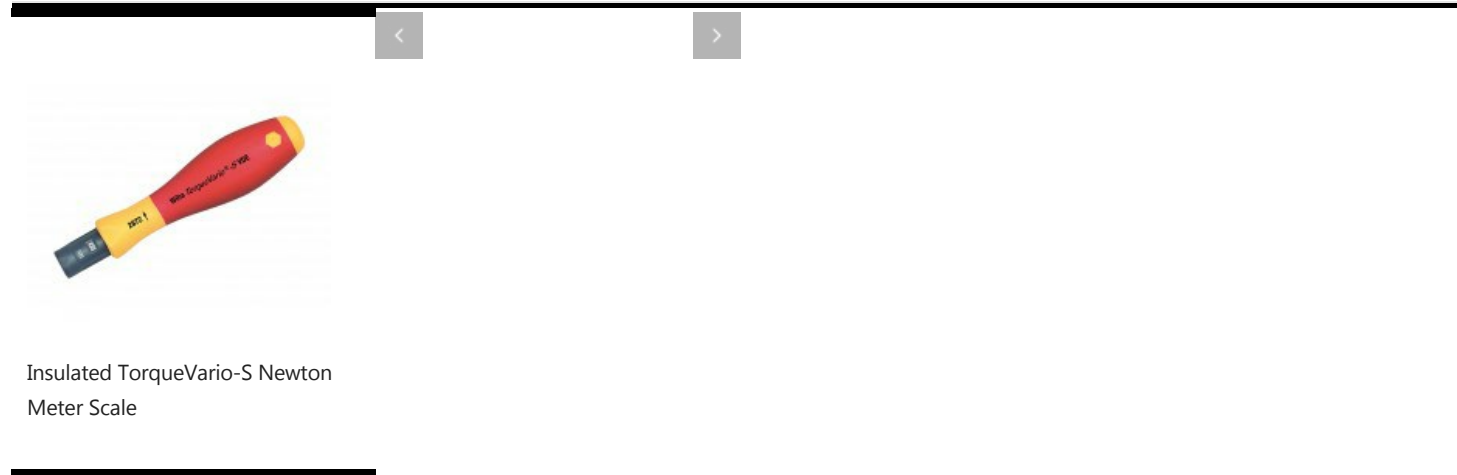

Insulated TorqueVario-S Newton
Meter Scale

Wiha Professional Quality Hand Tools



We produce Wiha products around the world under strict ISO quality standards. State of the art technology and special tool steels

assure products consistent with our reputation for outstanding performance in demanding service, repair and production applications.

[Discounts and promotions](#)

[Military Discount](#)

[IBEW-NECA Discount](#)

[Filter and sort all Wiha hand tools](#)

[Complete list of tools](#)

Wiha Tools USA Since 1985

Wiha Activities In the USA Started in August of 1985 bringing Wiha quality to professional tool users in North America. Our USA warehouse and distribution center services all 50 states & Our New Facilities In Canada Supply millions of tools from stock to professional quality conscious tool users throughout North America.

[About Us](#)

[Privacy Policy](#)

[Terms and Conditions](#)

[Having technical issues with the website?](#)

We accept

amazon pay

Wiha Tools USA Willi Hahn Corporation

A Subsidiary of [Wiha Werkzeuge GmbH](#)
[Schonach Germany](#)

**Monday - Friday Office Hours 7am - 5pm
CST USA**

1348 Dundas Cir,
Monticello, MN 55362
Customer Service Email:
cservice@wihatools.com
Tel: 763-295-6591
Fax: 763-295-6598

[Shipping](#)

[Returns](#)

[Warranty Info](#)

[About Us](#)

[Privacy Policy](#)

[Terms and Conditions](#)

**Over 5000 Professional Quality Wiha Tools
In Stock**



Newsletter

[Subscribe](#)