




+ CONNECTORS
COMBO JACKS

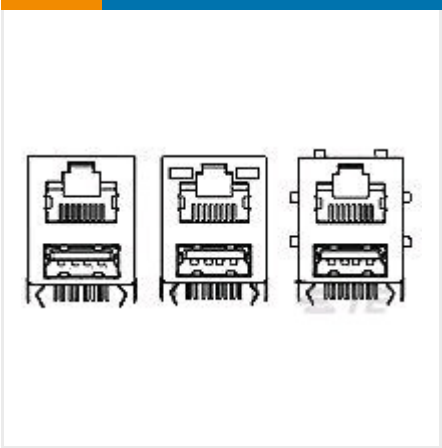

✓ Active

TE CONNECTIVITY (TE)
RJ45 OVER USB W/ LED GO/G

Modular Jacks & Plugs | A-RJ45

4-1775855-2
TE Internal Number: 4-1775855-2

EU RoHS Compliant
EU ELV Compliant

LED With

Number of Positions 4

Connector & Contact Terminates To Printed Circuit Board

↓ PRODUCT DRAWING
English

↓ 3D PDF

DOCUMENTATION

Product Drawings

Modular Jack RJ45 Stacked Over USB Conn. Dip Type

PDF
English

CAD Files

Customer View Model

2D_DXF.ZIP
English

3D PDF

PDF
3D

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

LED With
Connector & Contact Terminates To Printed Circuit Board
Product Type Connector
Size Standard
Connector Style Jack
PCB Mounting Orientation Right Angle

Configuration Features

Number of Positions 4
Panel Ground Without
Number of Ports 1

Body Features

Inverted Jack Face Yes
LED Color (Top Right) Green
Color Black
Shell Plating Material Nickel

Contact Features

Contact Base Material Phosphor Bronze

Termination Features

Termination Method Solder
Contact Termination Type Through Hole

Mechanical Attachment

Locating Posts Without
Locking Feature Without
PCB Mount Retention Type Kinked Legs, Straight Leg
Mounting Location Top

Housing Features

Housing Color Black

Dimensions

Tail Length 2.8 mm [.11 in]
PCB Thickness (Recommended) 1.6 mm [.063 in]

Operation/Application
Industrial USB Connector No

Industry Standards
USB-IF Test ID Number (TID) Not Submitted For Testing
UL Flammability Rating UL 94V-0

Packaging Features
Packaging Method Box & Tray, Tray
Packaging Quantity 50

Other
Comment RJ45 over USB

PRODUCT COMPLIANCE

+

Statement of Compliance
Statement of Compliance
PDF