


Data Sheet | Item Number: 2003-499

Test plug adapter N/L; for 2003-6641 and 2003-6640 Multilevel Installation Terminal Blocks; for vertical test slot; 2-pole; gray

<https://www.wago.com/2003-499>

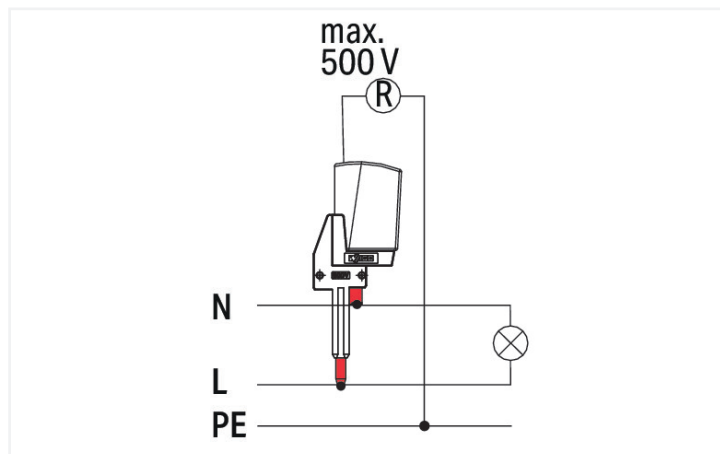

Color: gray

Electrical data

Ratings per IEC/EN	
Nominal voltage (III/3)	500 V
Rated impulse withstand voltage (III / 3)	6 kV
Rated current	16 A

General information

Wiring direction Side-entry wiring

Connection Data

Clamping units	1
Total number of potentials	1

Connection 1

Connection technology	CAGE CLAMP®
Solid conductor	0.5 ... 2.5 mm² / 20 ... 16 AWG
Stranded conductor	0.5 ... 1.5 mm² / 20 ... 16 AWG
Fine-stranded conductor	0.5 ... 2.5 mm² / 20 ... 16 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 inches
Wiring direction	Side-entry wiring

Material data

Note (material data)	Information on material specifications can be found here
Color	gray
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.056 MJ
Weight	3.3 g

Product Group	22 (TOPJOB S)
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821322115
Customs tariff number	85366990990

UNSPSC	39121410
eCl@ss 10.0	27-14-11-48
eCl@ss 9.0	27-14-11-48
ETIM 9.0	EC002555
ETIM 10.0	EC002555
ECCN	NO US CLASSIFICATION

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 2003-499	


Bid Text			
2003-499	19.02.2019	xml 2.59 KB	↓
2003-499	28.04.2017	doc 23.50 KB	↓



CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 2003-499	WSCAD Universe 2003-499
	

Installation Notes

Testing

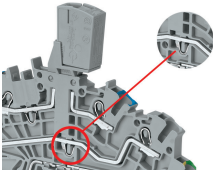

Multilevel installation terminal block fitted with an N/L-test plug adapter for quick and safe insulation resistance measurement of the connected N- and L-potentials