




**Part Number :** [150260620](#)

**Product Description :** 0.50mm Pitch Premo-Flex LVDS Jumper, 152.00mm Cable Length, Gold (Au) Plating, 20 Circuits

**Series Number :** 15026

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

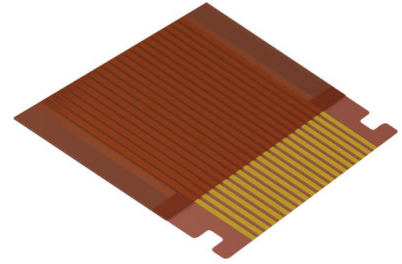

---

## Documents and Resources

### Drawings

[150260620 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


### Specifications

[150260001-000.pdf](#)

---

## Product Environment Compliance

### Compliance

|                    |   |
|--------------------|---|
| GADSL/IMDS         | Not Relevant  |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant  |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21  |
| REACH SVHC         | Not Contained per D(2025)7771-DC (04 Feb 2026)  |
| EU RoHS            | Compliant per EU 2015/863   |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

|              |  |
|--------------|--|
| Status       | Active   |
| Category     | Flat-Flexible Cable (FFC)  |
| Series       | 15026  |
| Description  | 0.50mm Pitch Premo-Flex LVDS Jumper, 152.00mm Cable Length, Gold (Au) Plating, 20 Circuits |
| Product Name | Premo-Flex LVDS Jumper   |
| UPC          | 195842679528   |

### Electrical

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A   |
| Voltage - Maximum             | 50V AC |

### Physical

|                               |                |
|-------------------------------|----------------|
| Cable Length                  | 152.00mm       |
| Circuits (Loaded)             | 20             |
| Contact Layout Type           | A (same side)  |
| Design Feature                | High-Speed     |
| Material - Outer Jacket       | Polyimide      |
| Material - Plating Mating     | Gold           |
| Packaging Type                | Bag            |
| Pitch - Mating Interface      | 0.50mm         |
| Temperature Range - Operating | -40° to +105°C |
| Termination Style             | FFC Connector  |
| Wire/Cable Type               | Flat Cable     |

---

|                 |     |
|-----------------|-----|
| Wire Size (AWG) | N/A |
|-----------------|-----|

---

## Mates With / Use With

### Mates with Part(s)

| Description  | Part Number       |
|--|-------------------|
| Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Right-Angle, Bottom Contact, 4.46mm Height, 105°C Operating Temperature, 20 Circuits, Gold (Au) Plating, with Ground Terminal | <u>2004850620</u> |
| Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Vertical, 5.60mm Height, 105°C Operating Temperature, 20 Circuits, Gold (Au) Plating, with Ground Terminal                    | <u>2004850720</u> |

---

This document was generated on May 13, 2026