


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/4/12

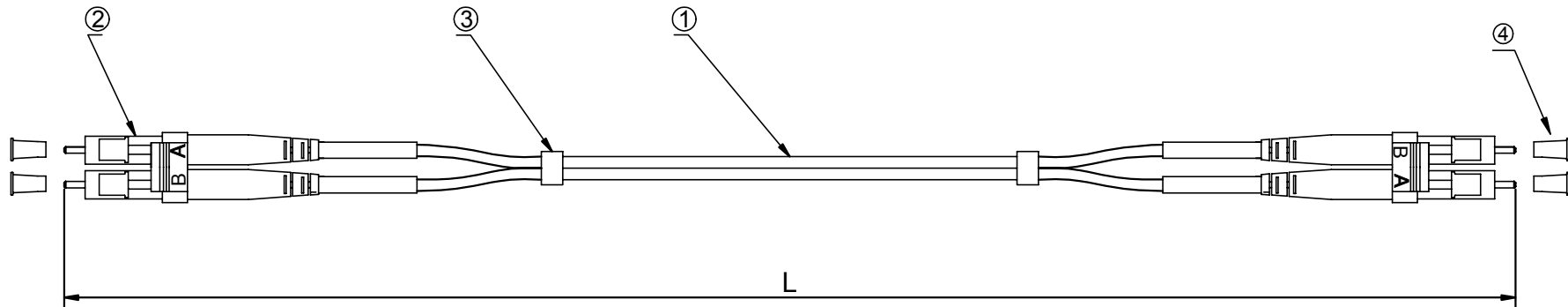

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
911M-2-1-00100-PL	671-446-A	1000±100	Orange
911M-2-1-00200-PL	671-446-B	2000±100	Orange
911M-2-1-00300-PL	671-446-C	3000±100	Orange
911M-2-1-00500-PL	671-446-D	5000±100	Orange
911M-2-1-00700-PL	671-446-E	7000±100	Orange
911M-2-1-01000-PL	671-446-F	10000±100	Orange
911M-2-1-01500-PL	671-446-G	15000±100	Orange
911M-2-1-02000-PL	671-446-H	20000±100	Orange
911M-2-1-02500-PL	671-446-I	25000±100	Orange

NOTES:
Insertion loss < 0.3 dB

6	
5	
4	Dust Cover
3	Shrinkage Tube
2	LC MM Duplex Connector (Beige housing White boot)
1	2.0mm,Duplex,MM-62.5/125 OM1, OFNP, Optical Fiber Cable(Orange)
No.	Description

CnC Tech, LLC Industrial Cable and Connector Technology					
		TITLE	Patch Cord, LC-LC,MM-62.5/125 OM1, Duplex, OFNP, Orange, 2.0mm, xxm		
UNIT	mm	P/N		DRAWN BY	
unless otherwise stated Tolerances mm XXX.XX ±0.3 XX.XX ±0.2 X.XX ±0.1		Customer P/N	911M-2-1-0xxxx-PL	CHECK BY	
		SIZE A4	SCALE Free	PAGE 1/1	APPROVAL BY