



**Part Number :** [1300660114](#)


**Product Description :** BradPower D-Size (1 3/8"-M35) Receptacle, 3 Poles, Female, 1/2" - 14 NPT, 10 AWG, 3.0m (9.84') Length

**Series Number :** 130066

**Status :** Active

**Product Category :** Circular Industrial Connectors

**Engineering Part Number :** CR3000A30M030

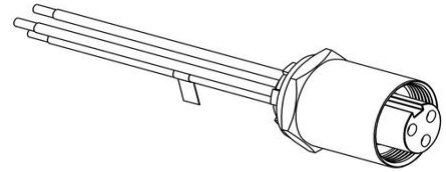

---

## Documents and Resources

### Drawings

[1300660114 sd.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

## UKCA - Declaration of Conformity

## CE - Declaration of Conformity

---

## Part Details

### General

Status	Active
Category	Circular Industrial Connectors
Series	130066
Description	BradPower D-Size (1 3/8"-M35) Receptacle, 3 Poles, Female, 1/2" - 14 NPT, 10 AWG, 3.0m (9.84') Length
IP Rating	IP67
Product Name	BradPower D-Size
Type	Single Ended (pigtail)
UPC	78678882335

### Agency

UL	E258922
----	---------

### Electrical

Current - Maximum per Contact	32.0A
Voltage - Maximum	600V AC/DC

### Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	3.0m
Material - Component	Clear Anodized Aluminum
Mounting Thread Size	1/2" - 14 NPT
Net Weight	366.000/g

Orientation	Straight
Panel Mount	Front
Poles	3
Temperature Range - Operating	-20° to +90°C
Wire/Cable Type	UL 1015
Wire Size (AWG)	10

---

This document was generated on Dec 31, 2025