



< List of part numbers with package codes >  
ECASD90J337M009K00

## Shape

L size	7.3 ±0.3mm
W size	4.3 ±0.3mm
T size	4.2 ±0.3mm
W1 size (max.)	2.4±0.2mm
S size	1.3±0.2mm
Size code in inch(mm)	2917(7343)

## References

Packaging	Specifications	Minimum quantity
K	φ330mm Embossed taping	2000







Mass (typ.)	
1 piece	0.29g

## Specifications

ESR (equivalent series resistance)	9mΩ
Capacitance	330μF ±20%
Rated voltage	6.3Vdc
Capacitance change rate	±20%
Operating temperature range	-40 to 105°C
Allowable Ripple Current	3.4Arms
Leakage Current	207.9μA

### ⚠ Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.  
2.This datasheet has only typical specifications because there is no space for detailed specifications.  
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

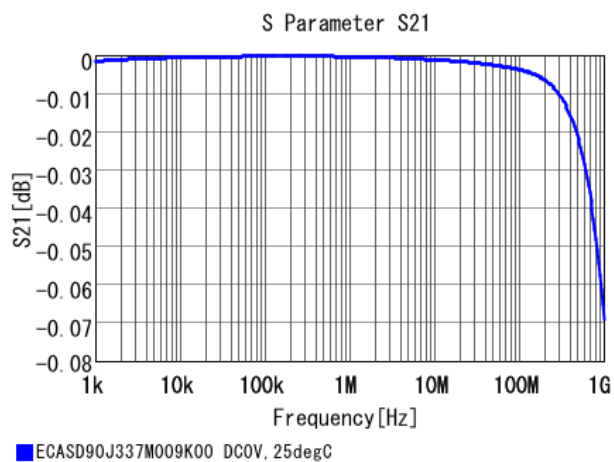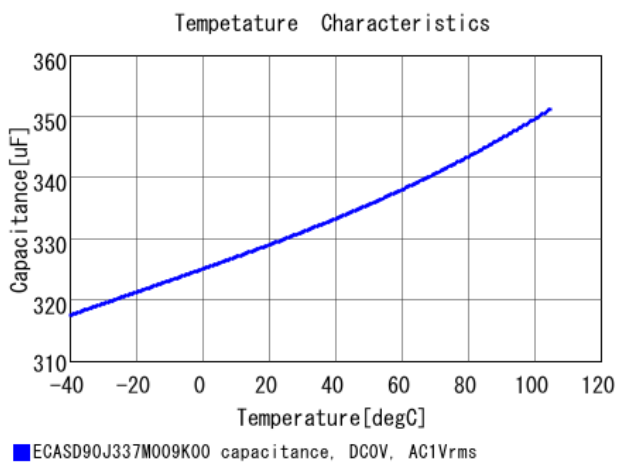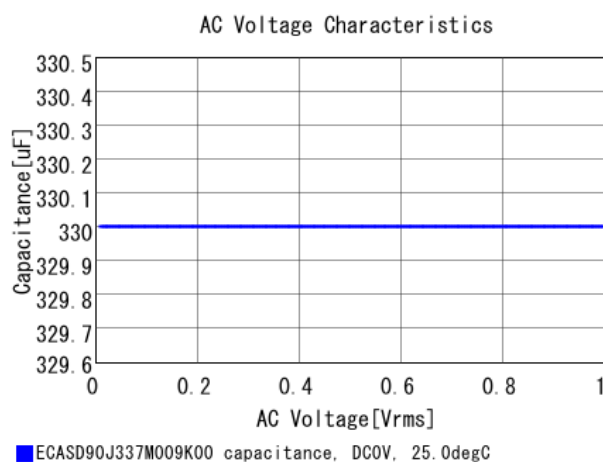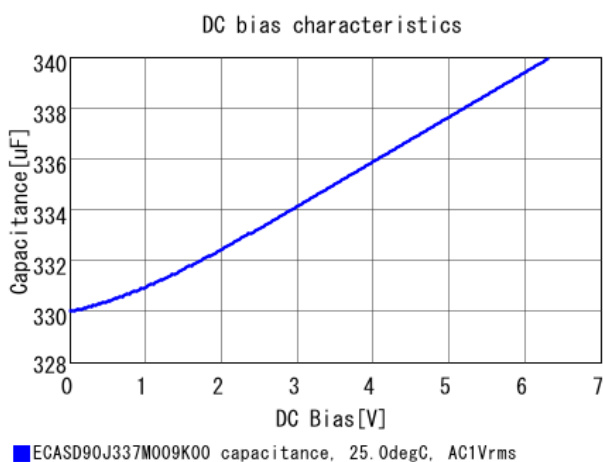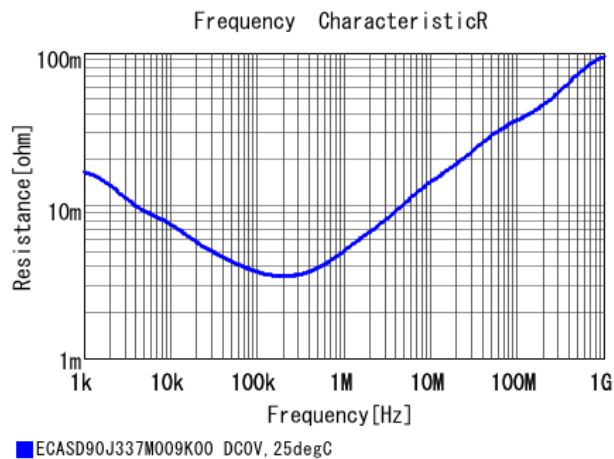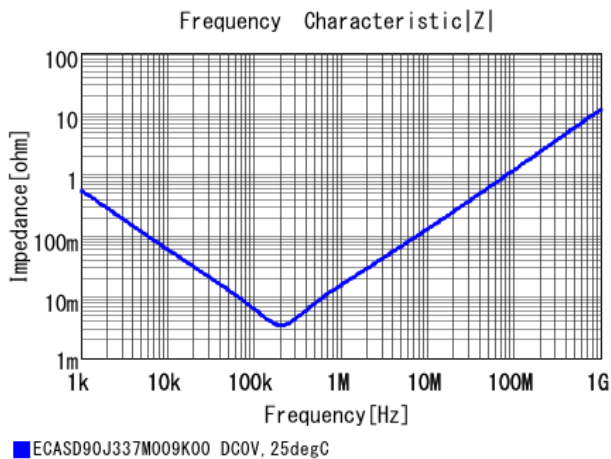

#### Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
  - 2.This datasheet has only typical specifications because there is no space for detailed specifications.
- Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.