


FC	PC "D" HOLE HOUSING ADAPTOR	Packaging : 1	F 7 2 9 7 0 8 2 0 0
	METALLIC ALIGNEMENT SLEEVE	Packaging : 100	F 7 2 9 7 1 8 2 0 0

Original dimensions in mm [inch]

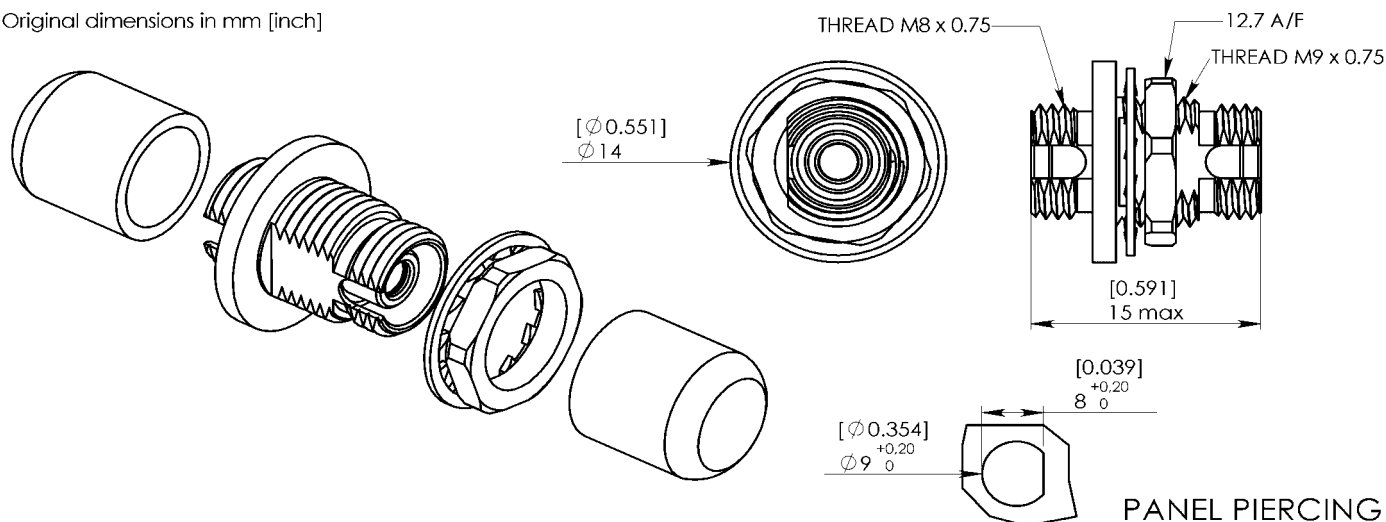

GENERAL

Type : IEC 61754-13 FC type. AI2 Screw Thread coupling

Mounting : " D " hole M9 max. panel thickness 2 mm

Alignment sleeve : Phosphor bronze

CHARACTERISTICS (Dependant on fiber or cable construction)

Material : brass, nickel plated

Optical : Attenuation (according to IEC 1300-3-4:Substitution method, 7 type) at 1310nm : 0,45 dB Max
0,15 dB Typ

Mechanical : *Durability* Bellcore 326, 200 cycles
Plug Retention > 100N

Environmental : **Temperature range** (storage/operating) -40°C to +85°C / -40°C to +70°C

Salt spray : EIA/TIA-455-16A, 35°C, 168 hr.

Vibration test : Bellcore 326, 10 to 50 Hz, 2 hrs./axis

Proof test : Bellcore 326, Straight pull : 10Kg load at 0°
Side pull : 4,5 Kg load at 90°

CREATION						RADIAL 101, rue P. Hoffmann - Z.I. Ouest 93116 ROSNY / BOIS Cedex-France Phone : (0033) 149353535 Fax : (0033) 48546363
N° :						
PEN/EP : CAT.						
Name : CAUSSE C.						
Date : 23 Juil99	1/09/02	performance specified			VALENCIA	
App. : LV	Issue	Revisions			Name App.	

4112-9212

This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary