



Color: ■ gray

Electrical data

Ratings per IEC/EN	
Rated current	125 A

Physical data

Width	29.1 mm / 1.146 inches
Jumper assignment	1-2

Material data

Note (material data)	Information on material specifications can be found here
Color	gray
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.05 MJ
Weight	15.1 g

Commercial data

PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	IN
GTIN	4045454074524
Customs tariff number	85366990990



Product classification	
UNSPSC	39121410
eCl@ss 10.0	27-14-11-40
eCl@ss 9.0	27-14-11-40
ETIM 9.0	EC000489
ETIM 8.0	EC000489
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 284-412

↓

Documentation				
Bid Text				
284-412	19.02.2019	xml	2.58 KB	↓
284-412	19.09.2017	doc	22.50 KB	↓


CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 284-412	EPLAN Data Portal 284-412
	WSCAD Universe 284-412
	ZUKEN Portal 284-412

Installation Notes

Commoning



Commoning with comb-style jumper bar. Individual arrangement: 125 A
Two jumpers combined in one clamping unit: 100 A

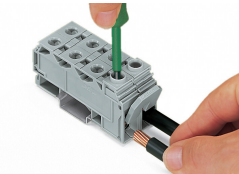

Connecting 35 mm² (2 AWG) conductors to commoned terminal blocks. Screw clamp connection, side-entry wiring

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com