




Home > 1/4 Round Swage Standoffs

1/4 ROUND SWAGE STANDOFFS

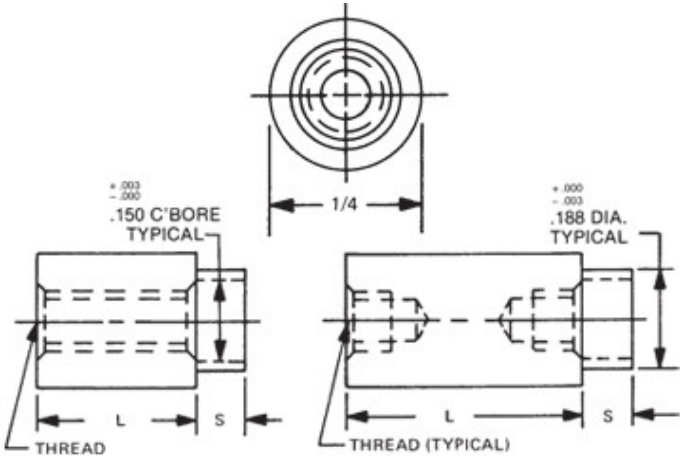

Home Previous Next

Related Metric

xxxxx	x	xxx	xx	x
Length	Shank	Thread	Material	Finish

PART: 3051 B 632 AL

Red ?'s show missing selections. [Help](#)

[Material Specifications](#)
[Ordering non-standard items](#)
[Download a Drawing](#)

CALL NOW:
203 888-2133



Qty1 *

Qty2

Qty3

3050

7/16

3050T

15/32

3051

1/2

3051T

17/32

Add to Cart

Swage Tool		
Punch	Anvil	Length
P-4	AR-22	3/32-3/16
P-4	AR-23	7/32-7/16
P-4	AR-24	15/32-11/16
P-4	AR-25	23/32-2"



☐	3052	9/16
☐	3052T	19/32
☐	3053	5/8
☐	3053T	21/32
☐	3054	11/16
☐	3054T	23/32
☐	3055	3/4
☐	3055T	25/32
☐	3056	13/16



Shank *

Select	S	0.003-0.003	P
☐	A	.075	1/32
☒	B	.105	1/16
☐	C	.135	3/32
☐	D	.165	1/8
☐	E	.230	3/16
☐	F	.290	1/4

Thread *

Select	Code	Thread
☐	256	2-56
☐	348	3-48
☐	440	4-40
☒	632	6-32

Material *

Select	Code	Material	RoHS
☒	AL	Aluminum	YES
☐	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES

Finish *

☐	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite*



1/4 Round Swage Standoffs

☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome
☐	11-Satin chrome
☐	12-Zinc

