




CT40400M, Cable Tie, 4" Max Bundle, 40 Lb Tensile, Natural

By Burndy
Catalog # [CT40400M](#)

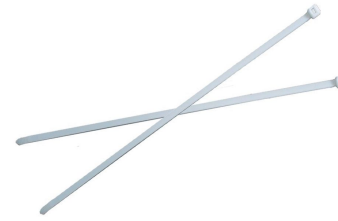

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - cULus	No
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
Certification - 94V0 Rated	N
UL Listed	No
Certification - UV Rated	No

Dimensions

Dimension - Width inch	0.14 in
Package Length	20.750 in
Dimension - Width mm	4 mm
Package Width	20.250 in
Package Weight	3.880 lb.
Dimension - L Length Overall mm	362 mm
Package Height	2.000 in
Length	14.25 in
Dimension - Bundle Diameter Max inch	4
Dimension - Length Overall inch	14.25 in

Width 0.14 in

Force Related

Rating - Minimum Tensile Strength lbs 40

General

Series	UNIRAP™ Series
Trade Name	UNIRAP™
Color	Natural
UPC 14 Digit GTIN	00781810332276
Material	NYLON 6/6
UPC	781810332276

Logistics

Minimum Pack Quantity	1000
Packaging Type	Bag
Carton Quantity	5000
Pallet Quantity	99999

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)

