



SIDE VIEW

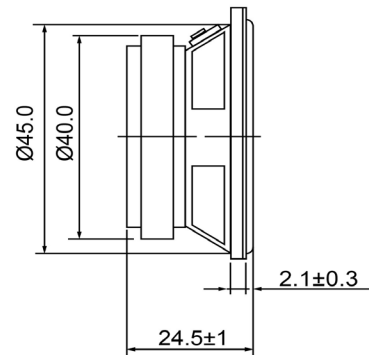

BOTTOM VIEW

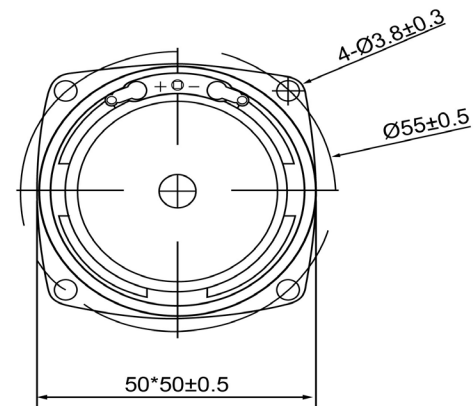

Specifications

Description	Value	Unit
Shape	Round	
Resonant Frequency	200	(Hz)
Frequency Range	200 ~ 18,000	(Hz)
SPL @ 10cm	85	(dBA)
Impedance	8	(Ohm)
Cone Material	Paper	
Nominal Power	5	(W)
Max Power	8	(W)
Mount Type	Frame Mount	
Operating Temperature	-25 ~ +55	°C
Storage Temperature	-25 ~ +55	°C
Weight	50	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

Dynamic Speaker

SP500208-1