


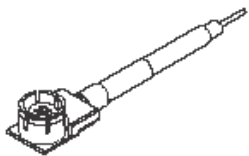

Part Number : [734120250](#)  
Product Description : MCRF-to-Pigtail, 1.13mm  
Cable Diameter, Length 102.00mm, 50 Ohms  
Series Number : 73412  
Status : Active  
Product Category : RF Cable Assemblies




## Documents & Resources

Drawings  
[Drawing 734120250\\_sd.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per ED/61/2018 (27 June 2018)
EU RoHS	Not Reviewed per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### EU RoHS Certificate of Compliance

## Part Details

## General

Status	Active
Category	RF Cable Assemblies
Series	73412
Description	MCRF-to-Pigtail, 1.13mm Cable Diameter, Length 102.00mm, 50 Ohms
Assembly Configuration	Single Ended Connector
Connector to Connector	MCRF-to-Pigtail
Product Family	RF Connectors, RF Cable Assemblies and RF Components
Product Name	MCRF
Type	RF Cable Assembly
UPC	822348137800

## Electrical

Impedance	50Ω
-----------	-----

## Physical

Cable Length	102.00mm
Gender	Plug-Pigtail
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Net Weight	0.370/g
Packaging Type	Bag
Single Ended	Yes
Wire/Cable Type	Coaxial

## Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

---

This document was generated on Dec 09, 2023