



Right-Angle Shapes, VG style 1156-4-GW24

Helashrink 1100 Series, with rib, Article number: 411-56684



Images (5)

Downloads

Features

- Used in conjunction with a circular grooved adaptor
- Provides strain relief and an environmental seal

Certifications & Approvals



Application

Heat Shrinkable moulded shapes for use in Electrical and Electronic Cable Harness Applications




More products in this product group

[Right-Angle Shapes, VG style >](#)

Base Data

Colour	Black (BK)
Description Short (BMEcat) (max. 150 characters)	Right-Angle Shape VG-Style with Rib for Plugs black, PO-X, up to 3:1
GLOBAL PART DESCRIPTION	1156-4-GW24-PO-X-BK
Pack Cont.	1 pc.
Package Quantity per	bag
Product Family	Helashrink 1100 Series, with rib
Product Group	Right-Angle Shapes, VG style
Shrink Ratio	up to 3:1
Variant	For plug

Product Dimensions

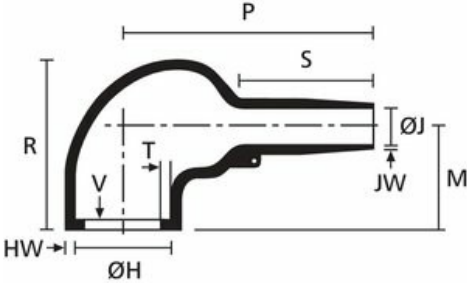

Angle	90 °
Flexibility	semi rigid
HW ± 20 %	1.8 mm
JO ± 10 %	15 mm
JW ± 20 %	1 mm
JW ± 30 %	1 mm
M nom.	26 mm
P ± 10 %	46 mm
R ± 10 %	38 mm
S nom.	15 mm
S ± 10 %	26 mm
T ± 10 %	1 mm
T ± 20 %	1 mm
V max.	3.3 mm
V ± 10 %	3 mm
øH max. b	22.5 mm
øH min. a	36 mm
øJ max. b	8.5 mm
øJ min. a	36 mm

Material and Specifications



Adhesive	W24
Designation as per VG-Norm	VG 95343 T18 D 004 A
Dielectric Strength	14 kV/mm according to ASTM D2671
ELV compliant (Article 4 - 2)	YES
Flammability	ASTM D635
Hazardous good	No
Material	Polyolefin, cross-linked (PO-X)
Min. Shrink Temperature - °C	+135 °C
Operating Temperature - °C	-75 °C to +150 °C
Specifications	  
Specifications	VG 95343-18:2012-08
Tensile Strength	15 MPa

Logistics and Packaging




More Information




ETIM 5.0	EC002464
ETIM 6.0	EC002464

Further information to 1156-4-GW24

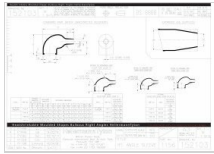

Technical drawing
152103_1_2

 [Download >](#)

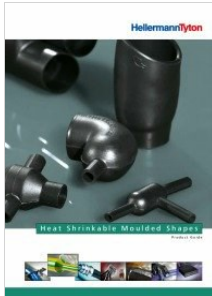

Moulded Shapes
Brochure 2016

 [Download >](#)

Competences



Heat shrink tubing

You are looking for the heat shrink tubing meeting your application requirements best? The key factors to which we owe our success are the unique and quite specific properties of our heat shrink tubing.

[Heat Shrink Tubing >](#)

Similar products



1158-4-HW8
411-58019
Right-Angle Shapes, VG
style



1158-4-J
411-58012
Right-Angle Shapes, VG
style



1158-4-JW8
411-58029
Right-Angle Shapes, VG
style



1159-4-B7
411-59001
Right-Angle Shapes, VG
style



1159-4-B7W8
411-59003
Right-Angle Shapes, VG
style



1159-4-B7WM250
411-59004
Right-Angle Shapes, VG
style

[Show all >](#)

Stay in touch with us!



Global Company

About us
Worldwide
Philosophy
Environment & Quality
Corporate Social
Responsibility

Products

Product overview
Cable Ties and Fixings
Insulation
Cable Protection Systems
Electrical Installation
Identification Systems

Competences

Cable Ties
Heat Shrink Tubing
Industrial Identification
and Self-Adhesive Labels
Cable Protection
Conduits

Markets & Industries

Automotive Industry
Solar plants
Wind turbines
Shipbuilding
Panel building
Rail industry

Media Centre

Videos
Product Catalogue
2018/2019
Automotive Catalogue
2016/2017
Connectivity Catalogues

Product Development
E-Business
ACADEMY
Careers
MADE FOR REAL

Application Tooling
Connectivity

Electrical Installation
Electrical tape
Wire connectors
Cable rods
Downlight covers
Cable jointing
Gel-filled cable joints
Cable Tie Guns
Connectivity Products
RFID tracking
Cable tie mounts
Thermal Transfer Printer
P-Clamp
Wiring ducts
Cable clips for edges
Cable management high
temperature
applications

Food Industry
Chemical Industry
Aerospace Industry
Defence Industry

2016/2017
Brochures
Software & Drivers
Helatag & Helafix
Templates
Manuals & Operating
Instructions

Events

Update: 07/10/2018

You can easily accept or reject the cookies on this site by choosing one of the following links:

[I accept cookies](#)

[I refuse cookies](#)

[Privacy](#)

[Contact](#) [Terms of Service](#) [Imprint](#) [Privacy Policy](#)

[statement](#)