

# CD 40X40 - Cable duct

3240189

<https://www.phoenixcontact.com/us/products/3240189>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable duct for installation and mounting in control cabinets, gray, comprising upper part and mounting base, width: 40 mm, height: 40 mm, length: 2000 mm

## Your advantages

- Predetermined breaking point enables tool-free, burr-free removal of bars
- Thanks to its leverage and special cutting geometry, the PPS CD cable duct cutter enables easy, burr-free cutting with minimum effort
- Easy, burr-free cutting with minimum effort using the CUTFOX-CD cable duct cutter
- The wide, diagonal heads of the cable duct bars make it easy to fit the cover and hold it securely in place
- Installed conductors are securely held in place by means of wire retaining clips that can be snapped onto bars on the side
- Plastic body-bound rivets enable easy fixing of cable ducts using the rivet setting tool

## Commercial data

Item number	3240189
Packing unit	26 pc
Minimum order quantity	26 pc
Sales key	BE74
Product key	BE7431
Catalog page	Page 581 (C-3-2019)
GTIN	4046356459143
Weight per piece (including packing)	752 g
Weight per piece (excluding packing)	695 g
Customs tariff number	39259020
Country of origin	DE

# CD 40X40 - Cable duct

3240189

<https://www.phoenixcontact.com/us/products/3240189>



## Technical data

### Product properties

Product type	Wiring duct
Data management status	
Article revision	05

### Dimensions

Dimensional drawing	
Width	40 mm
Height	40 mm
Length	2000 mm

### Material specifications

Color	Stone gray (RAL 7030)
Material	PVC
Flammability rating according to UL 94	V0
Components	Lead-free

### Cable/line

Halogen-free	no
--------------	----

### Mechanical properties

Usage cross-section	1235 mm² (100 %)
Number of cables at 60% filling volume	40 (2.5 mm² Ø 3.4 mm)

### Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-25 °C ... 60 °C

# CD 40X40 - Cable duct


3240189

<https://www.phoenixcontact.com/us/products/3240189>



## Drawings

Dimensional drawing

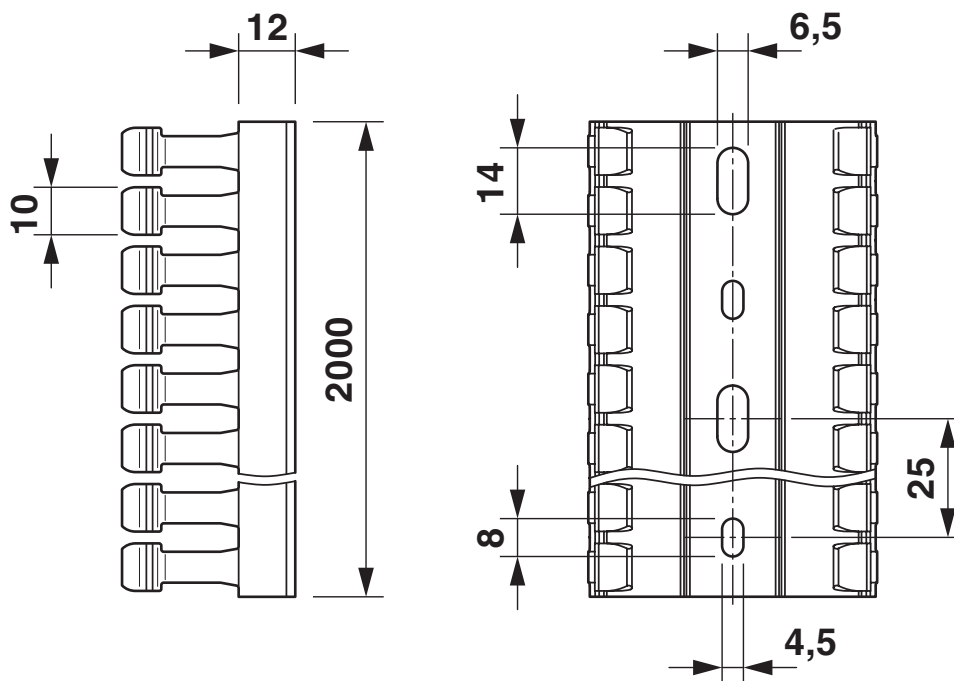

Base perforation according to DIN EN 50085

# CD 40X40 - Cable duct

3240189

<https://www.phoenixcontact.com/us/products/3240189>



## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3240189>



**CSA**

Approval ID: 80202282



**VDE Zeichengenehmigung**

Approval ID: 40058456



**UL Recognized**

Approval ID: E328576

# CD 40X40 - Cable duct

3240189

<https://www.phoenixcontact.com/us/products/3240189>



## Classifications

### ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

### ETIM

ETIM 9.0	EC000012
----------	----------

### UNSPSC

UNSPSC 21.0	39131700
-------------	----------

# CD 40X40 - Cable duct



3240189  
<https://www.phoenixcontact.com/us/products/3240189>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)