


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/4/12

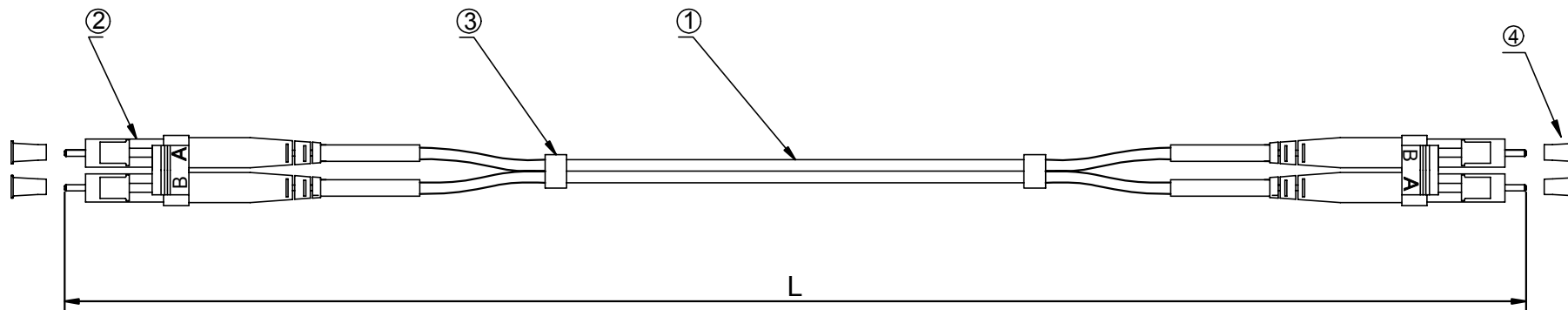

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
911S-2-5-00100	671-459-A	1000±100	Yellow
911S-2-5-00200	671-459-B	2000±100	Yellow
911S-2-5-00300	671-459-C	3000±100	Yellow
911S-2-5-00500	671-459-D	5000±100	Yellow
911S-2-5-00700	671-459-E	7000±100	Yellow
911S-2-5-01000	671-459-F	10000±100	Yellow
911S-2-5-01500	671-459-G	15000±100	Yellow
911S-2-5-02000	671-459-H	20000±100	Yellow
911S-2-5-02500	671-459-I	25000±100	Yellow

NOTES:

Insertion loss < 0.3 dB

Return loss > 50 dB

6	
5	
4	Dust Cover
3	Shrinkage Tube
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, PVC, Optical Fiber Cable(Yellow)
No.	Description

CnC Tech, LLC
Industrial Cable and Connector Technology

		TITLE	Patch Cord, LC-LC,SM-9/125 G652D, Duplex, PVC, yellow, 2.0mm, xxm		
UNIT	mm	P/N		DRAWN BY	
unless otherwise stated Tolerances mm XXX.XX ±0.3 ±2° XX.XX ±0.2 XXX ±0.1		Customer P/N	911S-2-5-0xxxx	CHECK BY	
		SIZE A4	SCALE Free	PAGE 1/1	APPROVAL BY