

M23 P HBMA-rotatable 25x25 2,7mm

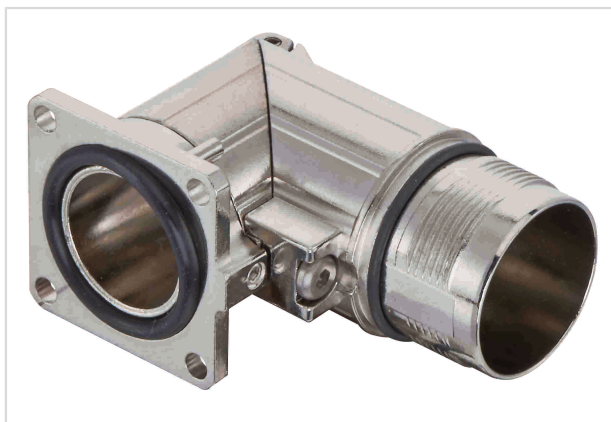


Image is for illustration purposes only. Please refer to product description.

Part number	09 15 600 0902
Specification	M23 P HBMA-rotatable 25x25 2,7mm
HARTING eCatalogue	https://b2b.harting.com/09156000902

Identification

Category	Hoods/Housings
Series	Circular connectors M23
Identification	Power
Type of hood/housing	Bulkhead mounted housing
Description of hood/housing	Angled Rotatable

Version

Size	M23
Fixing	Fixing hole 4x 2.75 mm
Locking type	Screw locking ComLock rapid locking

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP67 / IP69 / IPX9K acc. to ISO 20653 locked condition

Material properties

Material (hood/housing)	Copper-zinc alloy
Surface (hood/housing)	Nickel plated
Material (seal)	NBR
Colour (seal)	Black
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight



Pushing Performance

Material properties

ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
----------	-----------------------

Commercial data

Packaging size	5
Net weight	74.2 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440224 Shell for circular connectors